


- **Universal support arm**
- **Material :**  
Aluminium with steel screws


### Advantages

- Reliable operation
- Flexible mounting

**NEW!**

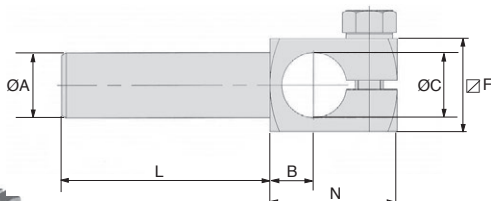

BDP20-50/R

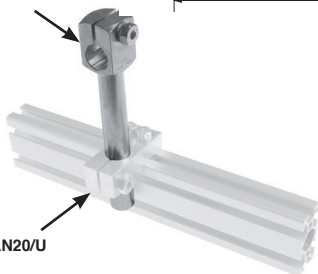

BAN20/U

Typical application

### DISCOUNTS

Qty	1+	10+	30+
Disc.	List	-5%	On request

Part number	ØA	B	ØC	L	∅F	N	Weight (g)	Price each 1 to 9
BDP20-50/R	20	15	20	50	25	35	61	33,90 €
BDP20-100/R	20	15	20	100	25	35	80	41,45 €
BDP20-150/R	20	15	20	150	25	35	95	43,49 €
BDP30-200/R	30	17	30	200	35	42	95	53,40 €

Dimensions in mm

## Altri prodotti...



BEAS  
Star shaped anti-static handle, Star, anti-static



PTRSS  
Pignone tendicatenena, Per ambienti aggressivi



ACLBMC  
Supporto per sensore per profili alluminio, Porta cellula



PGM52-M4  
Maniglia a ponte, Ottone



PSG25S  
Ingranaggio dritto di precisione, Inox 303



ZG2  
Ingranaggio dritto in plastica, Plastica lavorata (delrin)



CHMBR  
Braccio di reazione, Braccio di reazione per riduttori CHM e CHMR



AF  
Giunto rigido con cava chiavetta, Set screw



VRSS5S  
Anello di sollevamento, Orientabile maschio inox



MDB\_MTB  
Ingranaggio conico in plastica stampata, 3:1



H0  
Ingranaggio elicoidale ad assi incrociati a 90°, Acciaio 20NCD2



PSG125HC  
Ingran. dritto di precisione trattato skiving, Acciaio 20NCD2 cement...

## Prodotti correlati



BDP1R  
Braccio di reazione, Serraggio standard



BDP2R  
Braccio di reazione, Serraggio rinforzato