


- **Universal support arm**
- **Material :**
Aluminium with steel screws


Advantages

- **Reliable operation**
- **Flexible mounting**

NEW!

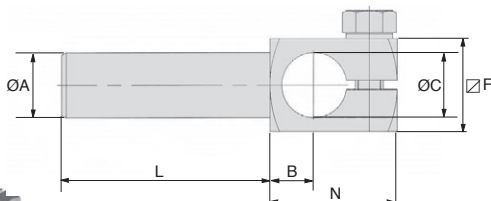

BDP20-50/R

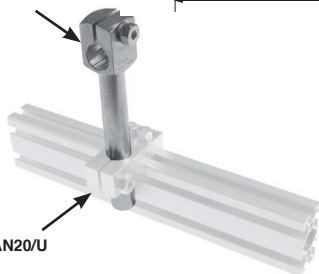

BAN20/U

Typical application

DISCOUNTS

Qty	1+	10+	30+
Disc.	List	-5%	On request

Part number	ØA	B	ØC	L	∅F	N	Weight (g)	Price each 1 to 9
BDP20-50/R	20	15	20	50	25	35	61	33,90 €
BDP20-100/R	20	15	20	100	25	35	80	41,45 €
BDP20-150/R	20	15	20	150	25	35	95	43,49 €
BDP30-200/R	30	17	30	200	35	42	95	53,40 €

Dimensions in mm

Altri prodotti...



GAL_25

Rullo per trasportatore, Senza cuscinetti a sfere



AKN

Giunto a soffietto Gerwah®, da 22 a 180Nm




PP50

Riduttore a ruota e vite senza fine, da 6.50 a 12.80 Nm




SBRtool

Chain tool, Drive chain maintenance tools

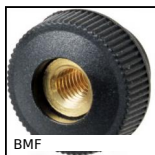

BMF

Manopola, Zigrinata - Passante

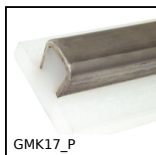

GMK17_P

Guida prodotto laterale piatta, Per imbottigliamento e imballaggio



FBL6000_K13

Spazzola al metro, Polipropilene nero striato (PP)



WSS

Gancio a S simmetrica, Acciaio



PRF_JL6

Panel accessories, Guarnizione - Ø 6mm



BVR

Battute a vite regolabile, Acciaio



SH2

Ingranaggio elicoidale ad assi paralleli,



BAGSS

Anello di bloccaggio inox, Inox

Prodotti correlati



BDP1R

Braccio di reazione, Serraggio standard



BDP2R

Braccio di reazione, Serraggio rinforzato