


- **Universal support arm**
- **Material :**
Aluminium with steel screws


Advantages

- Reliable operation
- Flexible mounting

NEW!

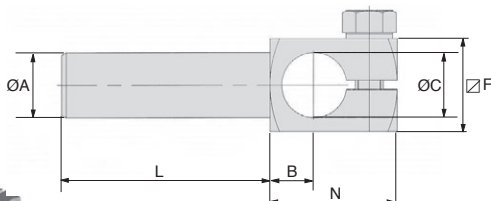

BDP20-50/R

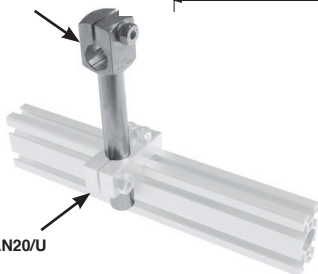

BAN20/U

Typical application

DISCOUNTS

Qty	1+	10+	30+
Disc.	List	-5%	On request

Part number	ØA	B	ØC	L	∅F	N	Weight (g)	Price each 1 to 9
BDP20-50/R	20	15	20	50	25	35	61	33,90 €
BDP20-100/R	20	15	20	100	25	35	80	41,45 €
BDP20-150/R	20	15	20	150	25	35	95	43,49 €
BDP30-200/R	30	17	30	200	35	42	95	53,40 €

Dimensions in mm

Altri prodotti...



CABma
Manicotto ovale per cavo, Per la crimpatura di un cavo in acciaio



RTN
Giunto Bowex®, a dentatura bombata, Nylon



VML
Volantino a lobi, Vite di pressione



RIMple
Ruota di livellamento, Con piastra



EHD06
Riduttore coassiale, da 8 a 19 Nm



SVG
Chiusura a leva regolabile, Corsa da 106,7mm a 121,4mm



M2
Coppia ruota e vite senza fine, Acciaio temprato



ADL_F
Anello di sollevamento, Inox



PLM-C
Magnete cilindrico di fermo, Magnete di fermo cilindrico



RFK58B
Riduttore ipoidale inox, fino a 500 Nm



PRF_RR
Elementi di giunzione, Piastra di raccordo



WING
Dado ad alette per serraggio manuale, Acciaio (ANSI B18-17)

Prodotti correlati



BDP1R
Braccio di reazione, Serraggio standard



BDP2R
Braccio di reazione, Serraggio rinforzato