


- **Universal support arm**
- **Material :**  
Aluminium with steel screws


### Advantages

- **Reliable operation**
- **Flexible mounting**

**NEW!**

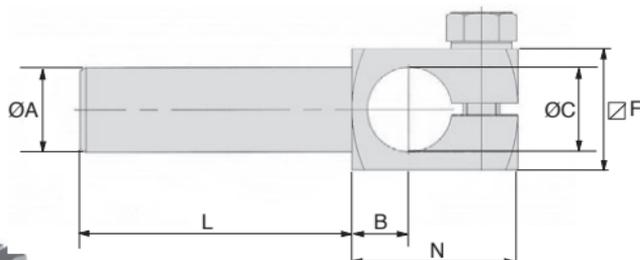

BDP20-50/R

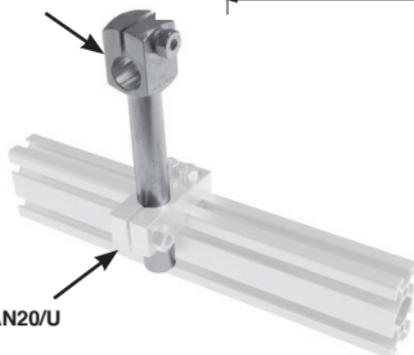

BAN20/U

Typical application

### DISCOUNTS

|       |      |     |            |
|-------|------|-----|------------|
| Qty   | 1+   | 10+ | 30+        |
| Disc. | List | -5% | On request |


| Part number | ØA | B  | ØC | L   | ∅F | N  | Weight (g) | Price each 1 to 9 |
|-------------|----|----|----|-----|----|----|------------|-------------------|
| BDP20-50/R  | 20 | 15 | 20 | 50  | 25 | 35 | 61         | 33,90 €           |
| BDP20-100/R | 20 | 15 | 20 | 100 | 25 | 35 | 80         | 41,45 €           |
| BDP20-150/R | 20 | 15 | 20 | 150 | 25 | 35 | 95         | 43,49 €           |
| BDP30-200/R | 30 | 17 | 30 | 200 | 35 | 42 | 95         | 53,40 €           |

Dimensions in mm

## Altri prodotti...



GPB5S  
Impugnatura sferica  
femmina filettata,  
Inox 304

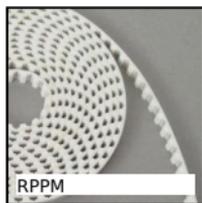

RPPM  
Cinghia aperta al  
metro tipo RPP, RPP5  
Poliuretano armatura  
in acciaio



SLV  
Attrezzo di bloccaggio  
a leva verticale, A  
leva verticale - acciaio



T5-BAR  
Barra dentata, T5



SH0  
Ingranaggio elicoidale  
ad assi paralleli,  
Acciaio 20NCD2



MFB\_MHB  
Ingranaggio conico in  
plastica stampata ,  
1.5:1



MDB\_MTB  
Ingranaggio conico in  
plastica stampata ,  
3:1



CHA35  
Cerniera ad avvitare,  
Hinge



VBFP  
Volantino a 6 lobi -  
boccola passante,  
Duroplast - Inox



PW\_PWG2  
Vite senza fine di  
precisione, Inox



HG6  
Ingranaggio dritto  
acciaio , Acciaio  
20NCD2



SER69K-CLE  
Chiusura 1/4 di giro  
per agroalimentare,  
Chiave

## Prodotti correlati



BDP1R  
Braccio di reazione,  
Serraggio standard



BDP2R  
Braccio di reazione,  
Serraggio rinforzato