

Single housed bearing





BH01

With tight fitting bearing

- Housing with tight fitting bearing
- ZZ bearing (with shielding)
- Materials:
Housing: zinc plated steel (60C40), natural finish
Bearing: steel



Options

- Flange with bearing retained by circlips (BH02)

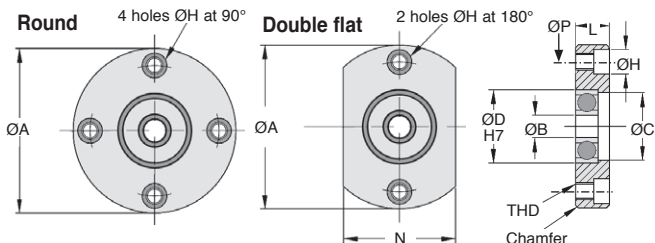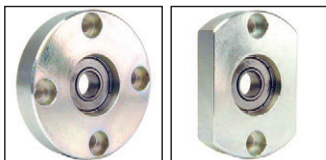

Part number			ØB	ØD	ØC	L	ØA
Round	Double flat	Square					
BH0100-40-623	BH0101-40-623	BH0102-40-623	3	Ø10x4Prof.	Ø8,5	8	40
BH0100-40-634	BH0101-40-634	BH0102-40-634	4	Ø16x5Prof.	Ø14,0	8	40
BH0100-40-625	BH0101-40-625	BH0102-40-625	5	Ø16x5Prof.	Ø14,0	8	40
BH0100-40-606	BH0101-40-606	BH0102-40-606	6	Ø17x6Prof.	Ø15,0	8	40
BH0100-58-608	BH0101-58-608	BH0102-58-608	8	Ø22x7Prof.	Ø19,5	12	58
BH0100-58-6000	BH0101-58-6000	BH0102-58-6000	10	Ø26x8Prof.	Ø24,0	12	58
BH0100-58-6201	BH0101-58-6201	BH0102-58-6201	12	Ø32x10Prof.	Ø28,0	12	58
BH0100-94-6202	BH0101-94-6202	BH0102-94-6202	15	Ø35x11Prof.	Ø33,0	18	94
BH0100-94-6003	BH0101-94-6003	BH0102-94-6003	17	Ø35x10Prof.	Ø33,0	18	94
BH0100-94-6004	BH0101-94-6004	BH0102-94-6004	20	Ø42x12Prof.	Ø38,0	18	94
BH0100-94-6005	BH0101-94-6005	BH0102-94-6005	25	Ø47x12Prof.	Ø43,0	18	94
BH0100-94-6006	BH0101-94-6006	BH0102-94-6006	30	Ø55x13Prof.	Ø50,0	18	94

Dimensions in mm

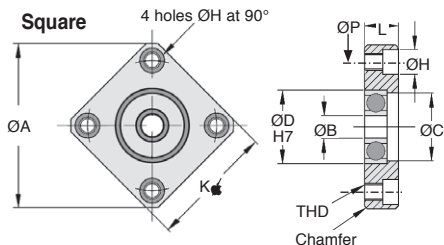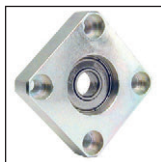

DISCOUNTS

Qty.	1+	6+	20+	40+
Disc.	List -15%	-20%	On request	

ØP	ØH	THD	K	Bearing	N	Price each 1 to 5		
						Round	Double flat	Square
30	Ø7,5x4,5Prof. (M4 Vis)	Ø4,20 (M5)	30	623ZZ	24	42,23 €	47,77 €	49,99 €
30	Ø7,5x4,5Prof. (M4 Vis)	Ø4,20 (M5)	30	634ZZ	24	42,23 €	47,77 €	49,99 €
30	Ø7,5x4,5Prof. (M4 Vis)	Ø4,20 (M5)	30	625ZZ	24	42,23 €	47,77 €	49,99 €
30	Ø7,5x4,5Prof. (M4 Vis)	Ø4,20 (M5)	30	606ZZ	24	42,23 €	47,77 €	49,99 €
46	Ø9,5x5,5Prof. (M5 Vis)	Ø5,20 (M6)	44	608ZZ	40	70,05 €	59,28 €	62,55 €
46	Ø9,5x5,5Prof. (M5 Vis)	Ø5,20 (M6)	44	6000ZZ	40	70,05 €	59,28 €	62,55 €
46	Ø9,5x5,5Prof. (M5 Vis)	Ø5,20 (M6)	44	6201ZZ	40	70,05 €	59,28 €	62,55 €
78	Ø15,0x8,5Prof. (M8 Vis)	Ø8,50 (M10)	77	6202ZZ	67	111,10 €	125,48 €	133,47 €
78	Ø15,0x8,5Prof. (M8 Vis)	Ø8,50 (M10)	77	6003ZZ	67	111,10 €	125,48 €	133,47 €
78	Ø15,0x8,5Prof. (M8 Vis)	Ø8,50 (M10)	77	6004ZZ	67	111,10 €	125,48 €	133,47 €
78	Ø15,0x8,5Prof. (M8 Vis)	Ø8,50 (M10)	77	6005ZZ	67	111,10 €	125,48 €	133,47 €
78	Ø15,0x8,5Prof. (M8 Vis)	Ø8,50 (M10)	77	6006ZZ	67	111,10 €	125,48 €	133,47 €

Dimensions in mm

Altri prodotti...



CHM30-MOT

Motoriduttore AC asincrono da 0,09 a 0,22kW, 0.09 a 0.22kW



PGNT

Impugnatura termoplastica a T, Con perno filettato



GAL48_OMNI

Ruota per trasportatore, Omnidirezionale



PHTss

Maniglia a ponte, Fino a 250°C




PM4

Vite senza fine, Acciaio temprato



MRAeco

Maglia rapida economica, Acciaio

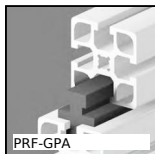

PRF-GPA

Guide for aluminium profile, Parallel rails



CHAK

Cerniera, Hi-Klik™ - di posizionamento



HTD5M_09

Puleggia dentata di trasmissione tipo HTD, HTD5 Alluminio



CHAR16046

Cerniera a molla, avvitabile



CFF

Testa a snodo femmina DIN ISO12240-4, Acciaio /



E20

Riduttore a rinvio angolare, da 0.60 a 3.84 Nm

Prodotti correlati



BH01

Cuscinetto radiale flangiato, Montaggio : pressione e colla



BH01

Cuscinetto radiale flangiato, Montaggio : pressione e colla