


BH02 Bearing retained by with circlips

- Bearing mounted in housing with circlips
- Housing supplied with bearing
- ZZ bearing (with shielding)
- Materials:
Housing: zinc plated steel (60C40), natural finish
Bearing: steel
Circlips: steel




Options

- Flange with bearing glued in (BH01)

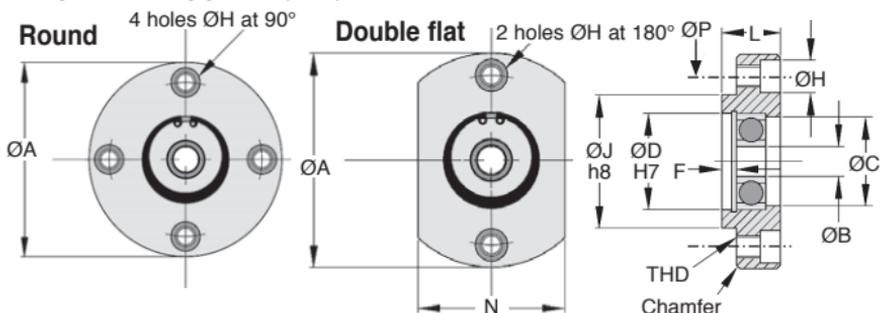

Part number			ØB	ØD	ØC	L	ØA	ØP
Round	Double flat	Square						
BH0200-40-623	BH0201-40-623	BH0202-40-623	3	Ø10x7Prof.	Ø8,5	11	40	30
BH0200-40-634	BH0201-40-634	BH0202-40-634	4	Ø16x8Prof.	Ø14,0	11	40	30
BH0200-40-625	BH0201-40-625	BH0202-40-625	5	Ø16x8Prof.	Ø14,0	11	40	30
BH0200-40-606	BH0201-40-606	BH0202-40-606	6	Ø17x9Prof.	Ø15,0	11	40	30
BH0200-58-608	BH0201-58-608	BH0202-58-608	8	Ø22x11Prof.	Ø19,5	16	58	46
BH0200-58-6000	BH0201-58-6000	BH0202-58-6000	10	Ø26x12Prof.	Ø24,0	16	58	46
BH0200-58-6201	BH0201-58-6201	BH0202-58-6201	12	Ø32x14Prof.	Ø28,0	16	58	46
BH0200-94-6202	BH0201-94-6202	BH0202-94-6202	15	Ø35x18Prof.	Ø33,0	25	94	78
BH0200-94-6003	BH0201-94-6003	BH0202-94-6003	17	Ø35x17Prof.	Ø33,0	25	94	78
BH0200-94-6004	BH0201-94-6004	BH0202-94-6004	20	Ø42x19Prof.	Ø38,0	25	94	78
BH0200-94-6005	BH0201-94-6005	BH0202-94-6005	25	Ø47x19Prof.	Ø43,0	25	94	78
BH0200-94-6006	BH0201-94-6006	BH0202-94-6006	30	Ø55x20Prof.	Ø50,0	25	94	78

Dimensions in mm

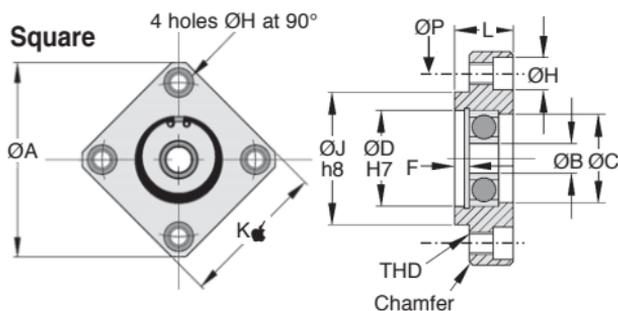

DISCOUNTS

Qty.	1+	6+	20+	40+
Disc.	List -15%	-20%	On request	

ØH	THD	K	Bearing	N	ØJ	F	Price each 1 to 5		
							Round	Double flat	Square
Ø7,5x4,5Prof. (M4 Vis)	Ø4,20 (M5)	30	623ZZ	24	Ø22x3	3	46,08 €	52,10 €	54,58 €
Ø7,5x4,5Prof. (M4 Vis)	Ø4,20 (M5)	30	634ZZ	24	Ø22x3	3	46,08 €	52,10 €	54,58 €
Ø7,5x4,5Prof. (M4 Vis)	Ø4,20 (M5)	30	625ZZ	24	Ø22x3	3	46,08 €	52,10 €	54,58 €
Ø7,5x4,5Prof. (M4 Vis)	Ø4,20 (M5)	30	606ZZ	24	Ø22x3	3	46,08 €	52,10 €	54,58 €
Ø9,5x5,5Prof. (M5 Vis)	Ø5,20 (M6)	44	608ZZ	40	Ø36x4	4	62,69 €	64,66 €	90,98 €
Ø9,5x5,5Prof. (M5 Vis)	Ø5,20 (M6)	44	6000ZZ	40	Ø36x4	4	62,69 €	64,66 €	90,98 €
Ø15,0x8,5Prof. (M8 Vis)	Ø5,20 (M6)	44	6201ZZ	40	Ø36x4	4	62,69 €	64,66 €	90,98 €
Ø15,0x8,5Prof. (M8 Vis)	Ø8,50 (M10)	77	6202ZZ	67	Ø66x6	7	90,93 €	102,62 €	145,64 €
Ø15,0x8,5Prof. (M8 Vis)	Ø8,50 (M10)	77	6003ZZ	67	Ø66x6	7	90,93 €	102,62 €	145,64 €
Ø15,0x8,5Prof. (M8 Vis)	Ø8,50 (M10)	77	6004ZZ	67	Ø66x6	7	90,90 €	102,62 €	145,64 €
Ø15,0x8,5Prof. (M8 Vis)	Ø8,50 (M10)	77	6005ZZ	67	Ø66x6	7	90,93 €	102,62 €	145,64 €
Ø15,0x8,5Prof. (M8 Vis)	Ø8,50 (M10)	77	6006ZZ	67	Ø66x6	7	77,93 €	102,62 €	145,64 €

Dimensions in mm

Altri prodotti...



EHD06

Riduttore coassiale,
da 8 a 19 Nm




VBFP

Volantino a 6 lobi -
boccola passante,
Duroplast - Ottone



RVM25

Riduttore manuale,
Rinvio angolare

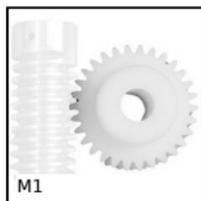

M1

Ruota per vite senza
fine, Plastica lavorata
(delrin)



MAX22

Motoriduttore DC 12V
e 24V DC, da 0,07 a
0,2Nm




BPLE

Sfera portante a
incastro, Leggero



GE32

Chiusura a leva rigida
ad anello, Standard

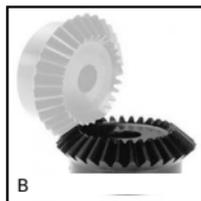

B

Ingranaggio conico -
Acciaio 60C40, 1:1



DHX

Spina cilindrica filetto
interno, estraibile DIN
7979D



BAB

Perno autobloccante a
sfere, Inox temprato



PRES4HR

Pressa manuale da
banco, Pressione fino
a 600kg



NT92

Riduttore coassiale a
treni paralleli, da 15 a
40 Nm - a treni paral...

Prodotti correlati



BH02

Cuscinetto radiale
flangiato, Montaggio
con circlips



BH02

Cuscinetto radiale
flangiato, Montaggio
con circlips