



- **Bearing mounted in housing with circlips**
- Housing supplied with bearing
- ZZ bearing (with shielding)
- **Materials:**  
Housing: zinc plated steel (60C40), natural finish  
Bearing: steel  
Circlips: steel

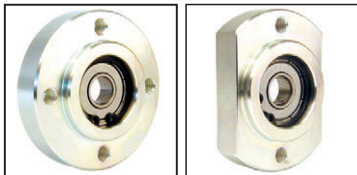



### Options

- Flange with bearing glued in (BH01)

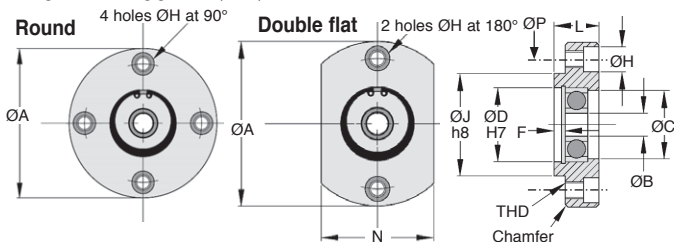

Part number			ØB	ØD	ØC	L	ØA	ØP
Round	Double flat	Square						
BH0200-40-623	BH0201-40-623	BH0202-40-623	3	Ø10x7Prof.	Ø8,5	11	40	30
BH0200-40-634	BH0201-40-634	BH0202-40-634	4	Ø16x8Prof.	Ø14,0	11	40	30
BH0200-40-625	BH0201-40-625	BH0202-40-625	5	Ø16x8Prof.	Ø14,0	11	40	30
BH0200-40-606	BH0201-40-606	BH0202-40-606	6	Ø17x9Prof.	Ø15,0	11	40	30
BH0200-58-608	BH0201-58-608	BH0202-58-608	8	Ø22x11Prof.	Ø19,5	16	58	46
BH0200-58-6000	BH0201-58-6000	BH0202-58-6000	10	Ø26x12Prof.	Ø24,0	16	58	46
BH0200-58-6201	BH0201-58-6201	BH0202-58-6201	12	Ø32x14Prof.	Ø28,0	16	58	46
BH0200-94-6202	BH0201-94-6202	BH0202-94-6202	15	Ø35x18Prof.	Ø33,0	25	94	78
BH0200-94-6003	BH0201-94-6003	BH0202-94-6003	17	Ø35x17Prof.	Ø33,0	25	94	78
BH0200-94-6004	BH0201-94-6004	BH0202-94-6004	20	Ø42x19Prof.	Ø38,0	25	94	78
BH0200-94-6005	BH0201-94-6005	BH0202-94-6005	25	Ø47x19Prof.	Ø43,0	25	94	78
BH0200-94-6006	BH0201-94-6006	BH0202-94-6006	30	Ø55x20Prof.	Ø50,0	25	94	78

Dimensions in mm

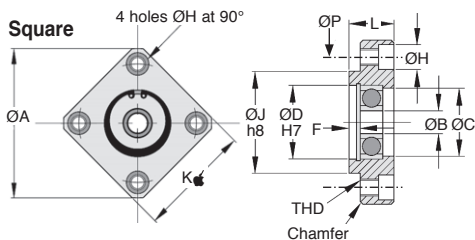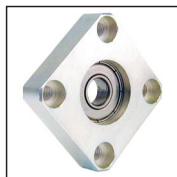

## DISCOUNTS

Qty.	1+	6+	20+	40+
Disc.	List -15%	-20%	On request	

							Price each 1 to 5		
ØH	THD	K	Bearing	N	ØJ	F	Round	Double flat	Square
Ø7,5x4,5Prof. (M4 Vis)	Ø4,20 (M5)	30	623ZZ	24	Ø22x3	3	46,08 €	52,10 €	54,58 €
Ø7,5x4,5Prof. (M4 Vis)	Ø4,20 (M5)	30	634ZZ	24	Ø22x3	3	46,08 €	52,10 €	54,58 €
Ø7,5x4,5Prof. (M4 Vis)	Ø4,20 (M5)	30	625ZZ	24	Ø22x3	3	46,08 €	52,10 €	54,58 €
Ø7,5x4,5Prof. (M4 Vis)	Ø4,20 (M5)	30	606ZZ	24	Ø22x3	3	46,08 €	52,10 €	54,58 €
Ø9,5x5,5Prof. (M5 Vis)	Ø5,20 (M6)	44	608ZZ	40	Ø36x4	4	62,69 €	64,66 €	90,98 €
Ø9,5x5,5Prof. (M5 Vis)	Ø5,20 (M6)	44	6000ZZ	40	Ø36x4	4	62,69 €	64,66 €	90,98 €
Ø15,0x8,5Prof. (M8 Vis)	Ø5,20 (M6)	44	6201ZZ	40	Ø36x4	4	62,69 €	64,66 €	90,98 €
Ø15,0x8,5Prof. (M8 Vis)	Ø8,50 (M10)	77	6202ZZ	67	Ø66x6	7	90,93 €	102,62 €	145,64 €
Ø15,0x8,5Prof. (M8 Vis)	Ø8,50 (M10)	77	6003ZZ	67	Ø66x6	7	90,93 €	102,62 €	145,64 €
Ø15,0x8,5Prof. (M8 Vis)	Ø8,50 (M10)	77	6004ZZ	67	Ø66x6	7	90,90 €	102,62 €	145,64 €
Ø15,0x8,5Prof. (M8 Vis)	Ø8,50 (M10)	77	6005ZZ	67	Ø66x6	7	90,93 €	102,62 €	145,64 €
Ø15,0x8,5Prof. (M8 Vis)	Ø8,50 (M10)	77	6006ZZ	67	Ø66x6	7	77,93 €	102,62 €	145,64 €


Dimensions in mm

## Altri prodotti...



PSG1HC

Ingran. dritto di precisione trattato skiving, Acciaio 20NCD2 cement...

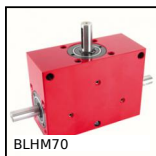

BLHM70

Rinvio angolare, fino a 128 Nm




PRF-SCREEN-5

Screen support, Support with 5 axes of rotation




PO

Maniglia a ponte - Multi-settore, Foro cieco maschiato

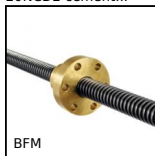

BFM

Dado trapezoidale, Bronzo - 1 filetto

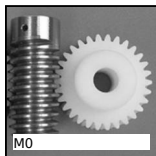


M0

Coppia ruota e vite senza fine , Plastica lavorata (delrin)



UCP\_SS

Cuscinetto ritto tutto inox, Inox

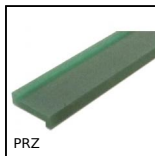


PRZ

Profilo supporto per catena, Profilo a Z da posare



RBNpl

Ruota fissa con piastra, Acciaio -

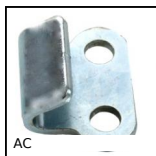

AC

Piastrina di riscontro, 18mm



BAN

Connettore / supporto per profili alluminio,



AZY

Antivibrante elastico cilindrico, Acciaio

## Prodotti correlati



BH02

Cuscinetto radiale flangiato, Montaggio con circlips



BH02

Cuscinetto radiale flangiato, Montaggio con circlips