
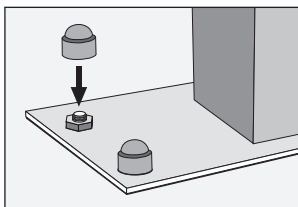


Hexagonal cap

BHEX

For hexagonal heads

- Cap for hexagonal headed screws or nuts
- Stylish, avoids risks of cuts
- Material:
Black technopolymer
- Supplied by the pack

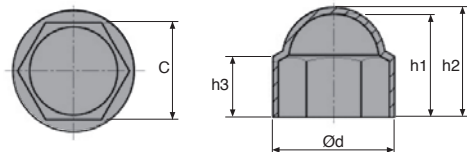

Typical application


DISCOUNTS

Qty	1+	5+	10+	25+
Disc.	List	-10%	-20%	On request

Part number	For thread	Size of hexagon	C	Ød	h1	h2	h3	Qty per pack	Stock*	Price each 1 to 4
BHEX-4/B	M4	7	6,9	9	7,5	8,3	3,5	100	-	18,60 €
BHEX-5/B	M5	8	7,9	10,9	8,5	9,5	5	100	✓	18,60 €
BHEX-6/B	M6	10	9,8	12,9	12,0	13,0	6	100	✓	18,60 €
BHEX-8/B	M8	13	12,8	16,8	14,0	15,0	9	100	✓	26,04 €
BHEX-10/B	M10	17	16,7	21,3	18,5	19,5	9	50	✓	14,88 €
BHEX-12/B	M12	19	18,7	23,6	20,0	21,5	11	50	✓	18,60 €
BHEX-14/B	M14	22	21,7	27,5	22,5	24,0	12	50	-	20,46 €
BHEX-16/B	M16	24	23,7	29,8	25,5	27,0	14	10	✓	7,06 €
BHEX-20/B	M20	30	29,8	37,7	31,0	33,2	17	10	✓	17,84 €
BHEX-24	M24	36	35,8	4,4	38,0	39,2	20	1	-	2,29 €
BHEX-30	M30	46	45,8	55,9	49,0	51,5	25	1	-	3,34 €

Dimensions in mm

Altri prodotti...

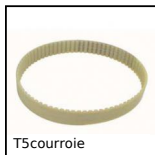

T5courroie

Cinghia di
posizionamento T, T5
Poliuretano armatura
in acciaio



HTD8M_30

Puleggia dentata di
trasmissione tipo
HTD, HTD8 Ghisa



JCDss

Giunto cardanico -
inox, Sollecitazioni
leggere



DBC

Panamech, Multi-
Beam, Alluminio - con
ganascia di serraggio



SSDB

Ingranaggio conico
inox, 2:1




BLHT60

Rinvio angolare a T,
da 26 a 70 Nm



SHTP

Tavola lineare
Drylin®, Economica

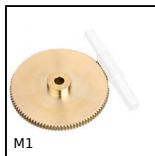

M1

Coppia ruota e vite
senza fine, Bronzo



GPBSS

Impugnatura sferica
femmina filettata,



GGP

Vite ad alette,
Tecnopolimero con



G2

Ingranaggio dritto
acciaio, Acciaio



DZYSS

Piedino antivibrante
cilindrico inox, inox

Prodotti correlati



VTH

Vite a testa
esagonale, Acciaio
classe 8.8



SHN

Dado esagonale -
DIN934, Acciaio (Class
6|8)