
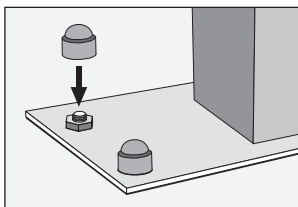


Hexagonal cap

BHEX

For hexagonal heads

- Cap for hexagonal headed screws or nuts
- Stylish, avoids risks of cuts
- Material:
Black technopolymer
- Supplied by the pack

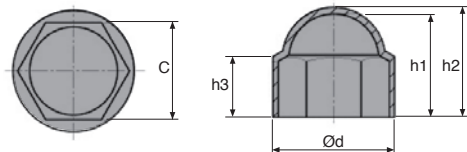

Typical application

DISCOUNTS

| | | | | |
|-------|------|------|------|------------|
| Qty | 1+ | 5+ | 10+ | 25+ |
| Disc. | List | -10% | -20% | On request |

| Part number | For thread | Size of hexagon | C | Ød | h1 | h2 | h3 | Qty per pack | Stock* | Price each 1 to 4 |
|-------------|------------|-----------------|------|------|------|------|-----|--------------|--------|-------------------|
| BHEX-4/B | M4 | 7 | 6,9 | 9 | 7,5 | 8,3 | 3,5 | 100 | - | 18,60 € |
| BHEX-5/B | M5 | 8 | 7,9 | 10,9 | 8,5 | 9,5 | 5 | 100 | ✓ | 18,60 € |
| BHEX-6/B | M6 | 10 | 9,8 | 12,9 | 12,0 | 13,0 | 6 | 100 | ✓ | 18,60 € |
| BHEX-8/B | M8 | 13 | 12,8 | 16,8 | 14,0 | 15,0 | 9 | 100 | ✓ | 26,04 € |
| BHEX-10/B | M10 | 17 | 16,7 | 21,3 | 18,5 | 19,5 | 9 | 50 | ✓ | 14,88 € |
| BHEX-12/B | M12 | 19 | 18,7 | 23,6 | 20,0 | 21,5 | 11 | 50 | ✓ | 18,60 € |
| BHEX-14/B | M14 | 22 | 21,7 | 27,5 | 22,5 | 24,0 | 12 | 50 | - | 20,46 € |
| BHEX-16/B | M16 | 24 | 23,7 | 29,8 | 25,5 | 27,0 | 14 | 10 | ✓ | 7,06 € |
| BHEX-20/B | M20 | 30 | 29,8 | 37,7 | 31,0 | 33,2 | 17 | 10 | ✓ | 17,84 € |
| BHEX-24 | M24 | 36 | 35,8 | 4,4 | 38,0 | 39,2 | 20 | 1 | - | 2,29 € |
| BHEX-30 | M30 | 46 | 45,8 | 55,9 | 49,0 | 51,5 | 25 | 1 | - | 3,34 € |

Dimensions in mm

Altri prodotti...



CLB_M
Maniglia a ripresa,
Zamak



SH1
Ingranaggio elicoidale
ad assi paralleli,
Plastica lavorata
(delrin)



AT5M AT10M
Cinghia aperta al
metro tipo AT, AT5
Poliuretano armatura
in acciaio



AT5-BAR
Barra dentata, AT5



KB_OP
Manicotto a sfere di
precisione, Di
precisione - acciaio



R203
Molla per stampi
ISO10243, Leggero



VTA
Limitatore di coppia
ad attrito Vari-Tork®,
0.53 a 1.32 Nm



SRP
Spina cilindrica
ISO8752, elastica ISO
8752



RFK28B
Riduttore ipoide inox,
fino a 130 Nm



Q6
Cuscinetto radiale a
sfere, Acciaio



CHM40
Riduttore a ruota e
vite senza fine, fino a
130 Nm



S4
Pignone a catena -
Inox, 4mm

Prodotti correlati



VTH
Vite a testa
esagonale, Acciaio
classe 8.8



SHN
Dado esagonale -
DIN934, Acciaio (Class
6[8])