
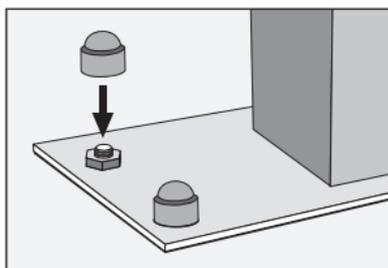


# Hexagonal cap

## BHEX

## For hexagonal heads

- Cap for hexagonal headed screws or nuts
- Stylish, avoids risks of cuts
- Material:  
Black technopolymer
- Supplied by the pack

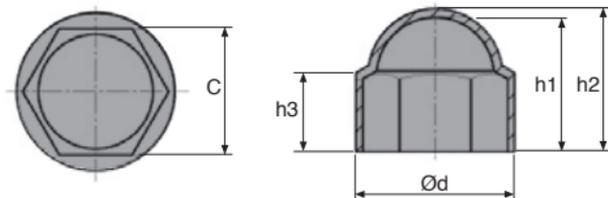

Typical application


### DISCOUNTS

Qty	1+	5+	10+	25+
Disc.	List	-10%	-20%	On request

Part number	For thread	Size of hexagon	C	Ød	h1	h2	h3	Qty per pack	Stock*	Price each 1 to 4
BHEX-4/B	M4	7	6,9	9	7,5	8,3	3,5	100	-	18,60 €
BHEX-5/B	M5	8	7,9	10,9	8,5	9,5	5	100	✓	18,60 €
BHEX-6/B	M6	10	9,8	12,9	12,0	13,0	6	100	✓	18,60 €
BHEX-8/B	M8	13	12,8	16,8	14,0	15,0	9	100	✓	26,04 €
BHEX-10/B	M10	17	16,7	21,3	18,5	19,5	9	50	✓	14,88 €
BHEX-12/B	M12	19	18,7	23,6	20,0	21,5	11	50	✓	18,60 €
BHEX-14/B	M14	22	21,7	27,5	22,5	24,0	12	50	-	20,46 €
BHEX-16/B	M16	24	23,7	29,8	25,5	27,0	14	10	✓	7,06 €
BHEX-20/B	M20	30	29,8	37,7	31,0	33,2	17	10	✓	17,84 €
BHEX-24	M24	36	35,8	4,4	38,0	39,2	20	1	-	2,29 €
BHEX-30	M30	46	45,8	55,9	49,0	51,5	25	1	-	3,34 €

Dimensions in mm

## Altri prodotti...

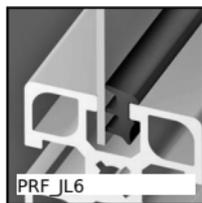

Panel accessories,  
Guarnizione - Ø 6mm



Anello di  
sollevamento, Acciaio



Staffa di montaggio  
per molla a gas,  
Staffa di montaggio  
piana per s...



Ingranaggio dritto  
acciaio, Acciaio  
20NCD2



Cuscinetto assiale a  
rulli cilindrici, Acciaio



Cerniera, Quadrata  
con rivetto e fori




Pignone di trazione,  
Serie 882



Volantino zigrinato,  
Zigrinato



Accessori per slitta di  
regolazione miniatura,  
30

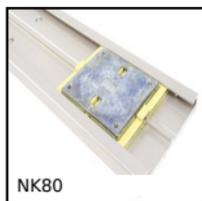

Guida mini Drylin® N,  
Larghezza 80mm



Perno folle eccentrico,  
Eccentrico



Ruota, Poliuretano -  
Mozzo alluminio (Ultra  
scorrevole)

## Prodotti correlati



Vite a testa  
esagonale, Acciaio  
classe 8.8



Dado esagonale -  
DIN934, Acciaio (Class  
6[8])