

# Right angled gearbox, double output shafts

## BLHM70



## Torque up to 128Nm



- The two outputs rotate in opposite directions
- Ratios of 1:1 to 2:1
- Output backlash  $\approx 1'$
- Max. speed: 4000 rpm
- Materials: casing: anodised aluminium  
input: hardened steel,  
output: hardened steel
- Weight: 8.76 kg

### Options

- Can be modified to your specifications

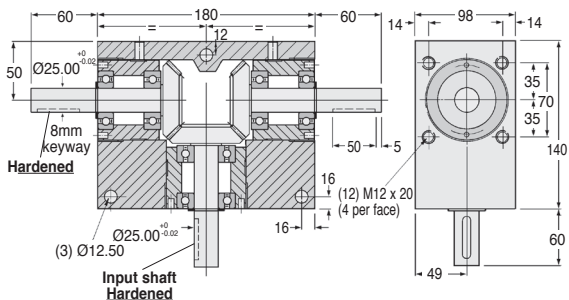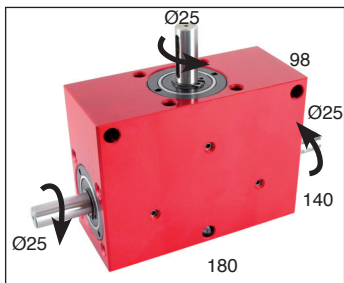

Output torque Nm (NM values given as a guide only)

Ratios	1:1	2:1
3000	43	26
2000	47	30
INPUT SPEED (rpm)	51	34
500	64	38
100	85	51
50	94	60
10	128	77

**Innovative!**  
Outputs rotate in different directions

### DISCOUNTS

Qty.	1+	2+	4+	6+
Disc.	List	-15%	-20%	On request

Part number	Ratio	Efficiency at 1000 rpm	Max. input speed (rpm)	Max. output speed (rpm)	Module	Price each
BLHM70-1	1:1	88%	3000	3000	4,0	2 152,92 €
BLHM70-2	2:1	88%	3000	1500	2,5	2 152,92 €

Dimensions in mm

## Altri prodotti...



BCFH  
Pomello a fungo Hygienic Usit®, Con perno filettato e collare alto



Q7  
Cuscinetto obliquo a sfere, Acciaio



MEB  
Ingranaggio conico in plastica stampata, 1:1



BPM\_LOK  
Pressore a molla con intaglio e puntale a sfera, LONG-LOK - Inox 303




PRES2HR  
Pressa manuale da banco, Pressione fino a 200kg



CHAsb28  
Cerniera senza perno in rotoli, Cerniera in polimero



DBL820  
Rotella per catena, Serie 820 e 815

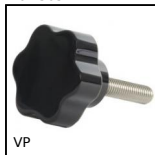


VP  
Volantino a 6 lobi, Duroplast - Acciaio



ETGamme  
Molla di trazione DIN2097, DIN 2097



EBM  
Cavallotto in acciaio, Acciaio

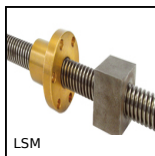

LSM  
Vite trapezoidale inox 316L, Inox - 1 filetto



PTA150  
Piede snodato con base stampata Ø150, Ø 150

## Prodotti correlati



BLH70  
Rinvio angolare a L, da 26 a 128 Nm



BLHT70  
Rinvio angolare a T, da 26 a 128 Nm