


Right angled gearbox, double output shafts

BLHM70


Torque up to 128Nm

- The two outputs rotate in opposite directions
- Ratios of 1:1 to 2:1
- Output backlash $\approx 1'$
- Max. speed: 4000 rpm
- Materials: casing: anodised aluminium
input: hardened steel,
output: hardened steel
- Weight: 8.76 kg

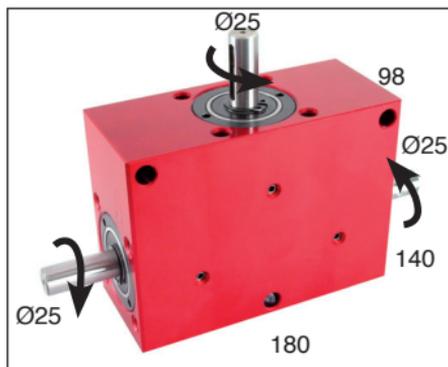

Options

- Can be modified to your specifications

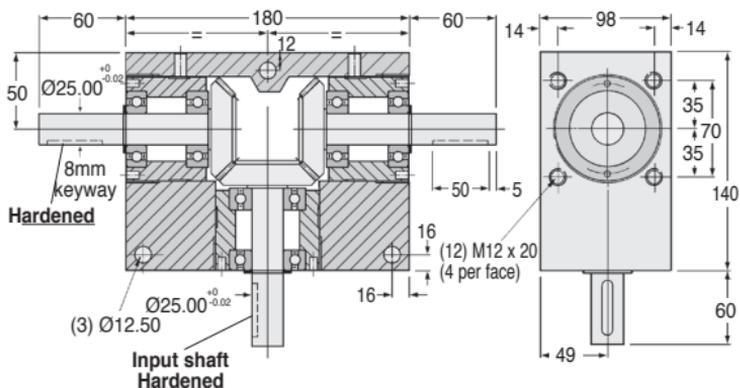

Output torque Nm (NM values given as a guide only)

Ratios	1:1	2:1
3000	43	26
2000	47	30
INPUT SPEED (rpm)	51	34
500	64	38
100	85	51
50	94	60
10	128	77

Innovative!
Outputs rotate in different directions

DISCOUNTS

Qty.	1+	2+	4+	6+
Disc.	List	-15%	-20%	On request

Part number	Ratio	Efficiency at 1000 rpm	Max. input speed (rpm)	Max. output speed (rpm)	Module	Price each
BLHM70-1	1:1	88%	3000	3000	4,0	2 152,92 €
BLHM70-2	2:1	88%	3000	1500	2,5	2 152,92 €

Dimensions in mm

Altri prodotti...



Pistoncino a molla,
inox



Ingranaggio dritto
acciaio - serie ECO,
Acciaio C45



Chiusura a leva con
serratura, Riscontro
grezzo




Accessori di
collegamento, Piatto
girevole



Economic mini-table
with trapezoidal
leadscrew, Economica



Riduttore a ruota e
vite senza fine, fino a
3,75 Nm

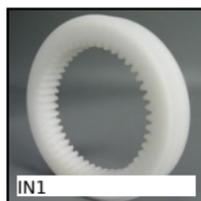

Ingranaggio interno,
Plastica lavorata
(delrin)



Giunto Bowex®, a
dentatura bombata,
Nylon e acciaio



Cinghia aperta al
metro tipo AT, AT10



Maniglia a ponte,
Termoplastica



Sfera portante alta
sporgenza, Leggero



Maniglia a ripresa -
maschio, Inox

Prodotti correlati



Rinvio angolare a L,
da 26 a 128 Nm



Rinvio angolare a T,
da 26 a 128 Nm