


- Element for square tube structure
- Material: reinforced polyamide

Info.

- Not sold individually, please contact us for details

Accessories

- Magnetic lock **SER**
- Hinge **CHA**
- Manual lock **LOQ**

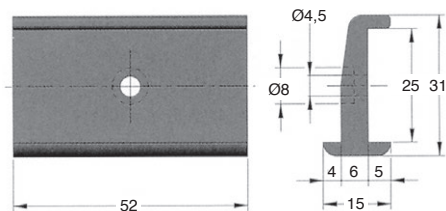

Typical application

DISCOUNTS

Qty.	1+	50+	100+
Disc.	List -5%	On request	

Part number	Weight (kg)	Stock*	Price each 1 to 49
BLOC-25	0,01	✓	4.03 €

*Depending on availability - Dimensions in mm

Altri prodotti...



UCFL_SS
Cuscinetto a flangia
ovale tutto inox, Inox



NKIB
Cuscinetto combinato
con anello interno,
Carico assiale
bidirezionale



WSSss
Gancio a S
simmetrica, Inox



PSG15
Ingranaggio dritto di
precisione, Acciaio
35NCD6 pretrattato



MSP38
Inserto con piastrina a
incollare
Masterplate®,
Cilindrico Ø38 con...



PO
Maniglia a ponte -
Multi-settore, Foro
liscio



NAST
Rotelle, Con anello
interno




ZG2
Ingranaggio dritto in
plastica, Plastica
lavorata (delrin)



SVR15
Martinetto a vite - Vite
rotante, Con
madrevite esterna



PR85
Piede fissabile con
snodo - poliammide, Ø
83

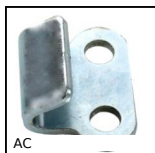

AC
Piastrina di riscontro,
18mm



HG5-ECO
Ingranaggio dritto
acciaio - serie ECO,
Acciaio C45

Prodotti correlati



CHA135
Cerniera ad avvitare,
135 gradi



LOQ
Accessori per porte,
Fermaporte a scatto