


- Element for square tube structure
- Material: reinforced polyamide

Info.

- Not sold individually, please contact us for details

Accessories

- Magnetic lock **SER**
- Hinge **CHA**
- Manual lock **LOQ**

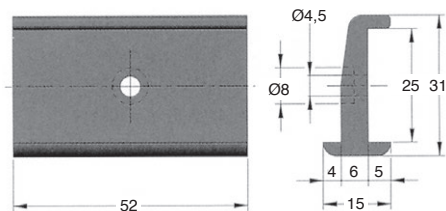

Typical application

DISCOUNTS

Qty.	1+	50+	100+
Disc.	List -5%	On request	

Part number	Weight (kg)	Stock*	Price each
BLOC-25	0,01	✓	4.03 €

*Depending on availability - Dimensions in mm

Altri prodotti...



YG1

Ingranaggio dritto
PRESTAZIONE, Acciaio
35NCD6



SRP

Spina cilindrica
ISO8752, elastica ISO
8752



AC

Piastrina di riscontro,
13mm



LRX

Guida lineare a rulli,
Carello - da 9410 N a
101000 N



DB

Ingranaggio conico in
acciaio, 2:1



GDR880

Guida dritta, Serie
880 e 881



BSCf

Manopola, Con coppia
regolabile



DOMI80

Slitta di regolazione
Domino 80, Slitta
DOMILINE 80 con
contatore e ...



LWH

Guida lineare a sfere -
Sfere acciaio, Binario -
da 9320 N a 71300 N



TS-10ECO

Puleggia dentata di
posizionamento tipo
T, Serie economica -



VTH

Vite a testa
esagonale, Acciaio
classe 8.8



PRF_PSA

Rotella per profilo
alluminio, Albero per
guida

Prodotti correlati



CHA135

Cerniera ad avvitare,
135 gradi



LOQ

Accessori per porte,
Fermaporte a scatto