

# Box set of hose clamps

## BOX-CS

## Steel

- Boxes containing solid 9 and 12mm wide hose clamps
- Ideal for the maintenance department

### Info.

- Also contains a flexible screwdriver



### Small version BOX-CS-100

Quantity	Range of adjustment Ø	Collar width
15	8-12	9
20	10-16	9
20	12-22	9
15	16-27	9
15	20-32	9
15	25-40	9

### Large version BOX-CS-220

Quantity	Range of adjustment Ø	Collar width
20	8-12	9
25	10-16	9
30	12-22	9
25	16-27	9
25	20-32	9
25	25-40	9
20	16-27	12
20	20-32	12
20	32-50	12
10	40-60	12

### DISCOUNTS

Qty	1+	2+	5+
Disc. Prix	-5%		On request

Part N°	Box dimensions	Quantity per box	Price each
BOX-CS-100	255x315x65	100 clamps	59,84 €
BOX-CS-220	460x360x85	220 clamps	124,68 €

All dimensions in mm

## Altri prodotti...



RURp

Rotella girevole con piastra, Poliuretano - Mozzo alluminio (Ultra S...



G0

Ingranaggio dritto acciaio, Acciaio 20NCD2




ACL-PL

Elementi di giunzione, Piastra di fissaggio - 86x86 mm



BAG-MISS

Anello di serraggio con intaglio e maniglia a leva, Inox

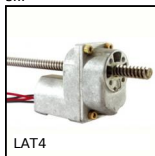


LAT4

Attuatore lineare a motore 4A, 4 ampere



PRF\_P

Elementi di ancoraggio, Base di ancoraggio

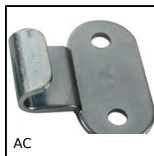

AC

Piastrina di riscontro, 20mm



T5-BAR

Barra dentata, T5



BPVMss

Sfera portante avvitabile miniatura, ...



AC156-157

Riscontro per chiusura a leva rigida ad ...



BCM\_MPBT

Spazzola cilindrica modulare, Filo ...



SLB

Pistoncino a molla, inox

### Prodotti correlati



BOX-CSss

Fascette di serraggio, Valigetta di fascette inox