

Box set of hose clamps

BOX-CS

Steel

- Boxes containing solid 9 and 12mm wide hose clamps
- Ideal for the maintenance department

Info.

- Also contains a flexible screwdriver



Small version BOX-CS-100

Quantity	Range of adjustment ØD	Collar width
15	8-12	9
20	10-16	9
20	12-22	9
15	16-27	9
15	20-32	9
15	25-40	9

Large version BOX-CS-220

Quantity	Range of adjustment ØD	Collar width
20	8-12	9
25	10-16	9
30	12-22	9
25	16-27	9
25	20-32	9
25	25-40	9
20	16-27	12
20	20-32	12
20	32-50	12
10	40-60	12

DISCOUNTS

Qty	1+	2+	5+
Disc. Prix	-5%		On request

Part N°	Box dimensions	Quantity per box	Price each
BOX-CS-100	255x315x65	100 clamps	59,84 €
BOX-CS-220	460x360x85	220 clamps	124,68 €

All dimensions in mm


Altri prodotti...



SVR20
Martinetto a vite - Vite rotante, Con madrevite esterna



RPCpl
Ruota fissa con piastra, Acciaio - Poliammide

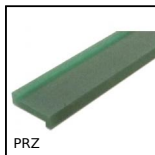

PRZ
Profilo supporto per catena, Profilo a Z ad incastro



RBG
Ruota, Rivestimento in gomma - nucleo in polipropilene



CABPVC
Cavo acciaio galvanizzato con PVC trasparente, Acciaio galvanizzato ...



WTM
Rondella per serraggio - DIN6340, Acciaio



SLBS
Pistoncino a molla, Tutto inox



M
Manicotto per giunto cardanico, Accessori



PTKFss
Piede speciale agroalimentare, Dado



CMM_SS
Testa a snodo maschio DIN



LRR
Chivistello con perno prismatico, Gancio



EFTC
Supporto di fissaggio, Inox

Prodotti correlati

economica



BOX-CSss
Fascette di serraggio, Valigetta di fascette inox