

Box set of hose clamps

BOX-CS

Steel

- Boxes containing solid 9 and 12mm wide hose clamps
- Ideal for the maintenance department

Info.

- Also contains a flexible screwdriver



Small version BOX-CS-100

Quantity	Range of adjustment Ø	Collar width
15	8-12	9
20	10-16	9
20	12-22	9
15	16-27	9
15	20-32	9
15	25-40	9

Large version BOX-CS-220

Quantity	Range of adjustment Ø	Collar width
20	8-12	9
25	10-16	9
30	12-22	9
25	16-27	9
25	20-32	9
25	25-40	9
20	16-27	12
20	20-32	12
20	32-50	12
10	40-60	12

DISCOUNTS

Qty	1+	2+	5+
Disc. Prix	-5%		On request

Part N°	Box dimensions	Quantity per box	Price each
BOX-CS-100	255x315x65	100 clamps	59,84 €
BOX-CS-220	460x360x85	220 clamps	124,68 €

All dimensions in mm

Altri prodotti...



VRSSss
Anello di sollevamento,
Orientabile maschio
inox



DCG
Ventosa, Gomma
naturale



GE_ES
Snodo sferico,
acciaio/acciaio



RDE-B
Rondella di tenuta
Hygienic Usit®,
Stainless steel - EPDM
blu



AT5P_AT10P
Piastra di giunzione
per cinghia AT, AT5




CHMR50
Riduttore a ruota e
vite senza fine, fino a
107 Nm



CHAsb63
Cerniera senza perno,
Cerniera in polimero




MFB_MHB
Ingranaggio conico in
plastica stampata,
1.5:1

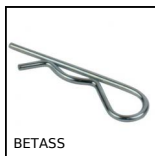

BETASS
Copiglia beta, Beta



SLB
Pistoncino a molla,
acciaio classe 5.8

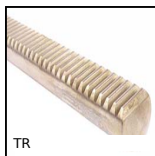

TR
Cremagliera sezione
circolare, Inox -



BEAS
Manopola, stella,
antistatico

Prodotti correlati



BOX-CSss
Fascette di serraggio,
Valigetta di fascette
inox