

Box set of hose clamps

Stainless steel

BOX-CS/SS

stainless steel

- Boxes containing solid 9 and 12mm wide hose clamps
- Ideal for the maintenance department

Info.

- Also contains a flexible screwdriver



Small version BOX-CS-100/SS

Quantity	Range of serrage Ø	largeur bande
15	8-12	9
20	10-16	9
20	12-22	9
15	16-27	9
15	20-32	9
15	25-40	9

Large version BOX-CS-220/SS

Quantity	Range of adjustment Ø	Collar width
20	8-12	9
25	10-16	9
30	12-22	9
25	16-27	9
25	20-32	9
25	25-40	9
20	16-27	12
20	20-32	12
20	32-50	12
10	40-60	12

DISCOUNTS

Qty	1+	2+	5+
Disc. Prix	-5%	-5%	On request

Part N°	Box dimensions	Quantity per box	Price each
BOX-CS-100/SS	255x315x65	100 clamps	97,25 €
BOX-CS-220/SS	460x360x85	220 clamps	184,03 €

All dimensions in mm

Fax 0 825 88 6000
Service 0,15 € / min
+ prix appel

cial2@hpceurope.com

HPC

SUPPLEMENT 2019

207

Altri prodotti...



DB

Ingranaggio conico in acciaio, 2:1



PLM-SC

Magnete piatto, With threaded hole



HDSS

Giunto cardanico - inox, Sollecitazioni intense



CHM30-MOT

Motoriduttore AC asincrono da 0,09 a 0,22kW, 0.09 a 0.22kW



BTE

Tenditore automatico universale, Per applicazioni correnti



ERC

Terminale rapido per cavi, A forcella



HRV

Sistema di guida su binario a V Simple Select®, Binario con carrello



TBE12

Economic mini-table with trapezoidal leadscrew, 2kg



T10_21_AL

Puleggia dentata di posizionamento tipo T, Serie economica -




BH01

Cuscinetto radiale flangiato, Montaggio : pressione e colla



BABPass

Perno autobloccante inox temprato ad anello, Con

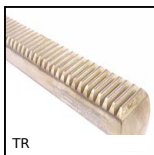

TR

Cremagliera sezione circolare, Inox - modulo 0,25-1,5

Prodotti correlati



BOX-CS

Fascette di serraggio, Valigetta di fascette acciaio