

Box set of hose clamps

Stainless steel

BOX-CS/SS

- Boxes containing solid 9 and 12mm wide hose clamps
- Ideal for the maintenance department

Info.

- Also contains a flexible screwdriver



stainless steel



Small version BOX-CS-100/SS

Quantity	Range of serrage Ø	largeur bande
15	8-12	9
20	10-16	9
20	12-22	9
15	16-27	9
15	20-32	9
15	25-40	9

Large version BOX-CS-220/SS

Quantity	Range of adjustment Ø	Collar width
20	8-12	9
25	10-16	9
30	12-22	9
25	16-27	9
25	20-32	9
25	25-40	9
20	16-27	12
20	20-32	12
20	32-50	12
10	40-60	12

DISCOUNTS

Qty	1+	2+	5+
Disc. Prix	-5%	-5%	On request

Part N°	Box dimensions	Quantity per box	Price each
BOX-CS-100/SS	255x315x65	100 clamps	97,25 €
BOX-CS-220/SS	460x360x85	220 clamps	184,03 €

All dimensions in mm

Fax 0 825 88 6000
Service 0,15 € / min
+ prix appel

cial2@hpceurope.com

HPC

SUPPLEMENT 2019

207

Altri prodotti...



HG6

Ingranaggio dritto
acciaio , Acciaio
20NCD2




PTAF80-PAMF80

Piede fissabile con
base lamiera Ø80, Ø
80



LVT

Mini martinetto
motorizzato 1A, 1
ampere

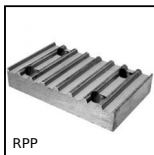

RPP

Piastra di giunzione
per cinghia RPP,
RPP14



ACLBT5

Sistema di chiusura,
Blocca porta a sfera



NK17

Guida mini Drylin® N,
Larghezza 17 mm



GE14

Chiusura a leva, Con
porta-lucchetto



GBS

Dado per vite a sfere,
Dado flangiato



HAS

Rondella girevole, Vite
con spalla a testa
piatta con intaglio




NKX

Cuscinetto combinato
senza anello interno,
Needle and roller



SSDB

Ingranaggio conico
inox, 2:1

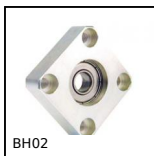

BH02

Cuscinetto radiale
flangiato, Montaggio
con circlips

Prodotti correlati



BOX-CS

Fascette di serraggio,
Valigetta di fascette
acciaio