

# Box set of hose clamps

Stainless steel

BOX-CS/SS

- Boxes containing solid 9 and 12mm wide hose clamps
- Ideal for the maintenance department

## Info.

- Also contains a flexible screwdriver



stainless steel



### Small version BOX-CS-100/SS

Quantity	Range of serrage Ø	largeur bande
15	8-12	9
20	10-16	9
20	12-22	9
15	16-27	9
15	20-32	9
15	25-40	9

### Large version BOX-CS-220/SS

Quantity	Range of adjustment Ø	Collar width
20	8-12	9
25	10-16	9
30	12-22	9
25	16-27	9
25	20-32	9
25	25-40	9
20	16-27	12
20	20-32	12
20	32-50	12
10	40-60	12

## DISCOUNTS

Qty	1+	2+	5+
Disc. Prix	-5%	-5%	On request

Part N°	Box dimensions	Quantity per box	Price each
BOX-CS-100/SS	255x315x65	100 clamps	97,25 €
BOX-CS-220/SS	460x360x85	220 clamps	184,03 €

All dimensions in mm

**0 825 88 6000**  
Service 0,15 € / min  
+ prix appel

Fax

cial2@hpceurope.com

HPC

SUPPLEMENT 2019

207

## Altri prodotti...



DH

Spina cilindrica,  
standard DIN 6325



GE

Chiusura a leva,  
Standard



CLR

Staffa di montaggio  
per molla a gas,  
Staffa di montaggio  
per forcell...




KB\_UU

Manicotto a sfere di  
precisione, Di  
precisione - acciaio



HW\_HT

Guida su semi-binari,  
Ruota

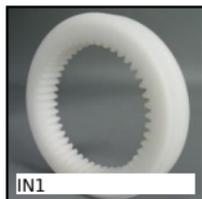

IN1

Ingranaggio interno,  
Plastica lavorata  
(delrin)



ESCON

Accessori per  
variatore di velocità  
5A, Cavo USB per  
connessione PC



CAP805

Catena a tapparella  
dritta, Large serie 805



CMM

Testa a snodo  
maschio DIN



V3RA

Volantino a tre razze,  
Poliammide



NPTF20

Morsetto di  
collegamento, Fisso



EMS

Volantino zigrinato,  
Zigrinato

## Prodotti correlati



BOX-CS

Fascette di serraggio,  
Valigetta di fascette  
acciaio