

Box set of hose clamps

Stainless steel

BOX-CS/SS

stainless steel

- Boxes containing solid 9 and 12mm wide hose clamps
- Ideal for the maintenance department

Info.

- Also contains a flexible screwdriver



Small version BOX-CS-100/SS

Quantity	Range of serrage Ø	largeur bande
15	8-12	9
20	10-16	9
20	12-22	9
15	16-27	9
15	20-32	9
15	25-40	9

Large version BOX-CS-220/SS

Quantity	Range of adjustment Ø	Collar width
20	8-12	9
25	10-16	9
30	12-22	9
25	16-27	9
25	20-32	9
25	25-40	9
20	16-27	12
20	20-32	12
20	32-50	12
10	40-60	12

DISCOUNTS

Qty	1+	2+	5+
Disc. Prix	-5%	-5%	On request

Part N°	Box dimensions	Quantity per box	Price each
BOX-CS-100/SS	255x315x65	100 clamps	97,25 €
BOX-CS-220/SS	460x360x85	220 clamps	184,03 €

All dimensions in mm

Fax 0 825 88 6000
Service 0,15 € / min
+ prix appel

Altri prodotti...



CHA

Cerniera, Robusta -
Apertura 180°



HBM

Guida su semi-binari,
Boccola di regolazione



BAGTr

Anello di tenuta per
vite trapezoidale,
Alluminio




RMSA

Deceleratore,
Regolabile



T5P_T10P

Piastra di giunzione
per cinghia T, T10

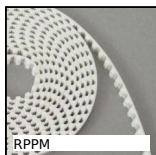


RPPM

Cinghia aperta al
metro tipo RPP, RPP8
Poliuretano armatura
in acciaio



BABreceptacle

Perno autobloccante,
Bussola di innesto

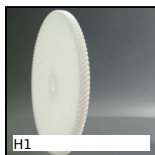


H1

Ingranaggio elicoidale
ad assi incrociati a
90°, Plastica lavorata




KB_WW

Manicotto chiuso a
sfere di precisione,

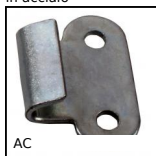

AC

Piastrina di riscontro,
15mm

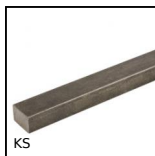

KS

Chiavetta in barre,
Acciaio - in barre



M1

Coppia ruota e vite
senza fine, Bronzo

Prodotti correlati



BOX-CS

Fascette di serraggio,
Valigetta di fascette
acciaio