

Box set of Nitrile O-rings

BOX-TOR-A Diameters from 2.9x1.78mm to 28.17x3.53mm



- Assortment conforming to AS/BS standard
- 30 different sizes
- Material:
Nitrile NBR 70 Shore A
- Working temperature: -30 to +110°C

Uses

- Suitable for:
- Hydraulic oils
 - HFA fluids
 - HFB fluids
 - HFC fluids
 - Air

Info

- Ideal for the maintenance department

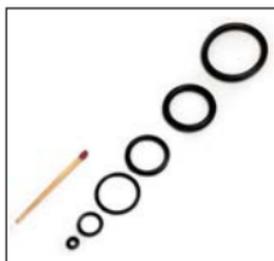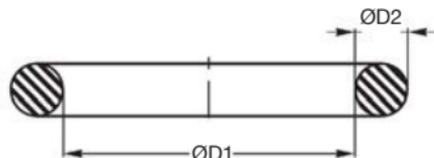

Box contents

Quantity	ØD1	ØD2	Quantity	ØD1	ØD2	Quantity	ØD1	ØD2
20	2,90	1,78	10	15,60	1,78	5	20,29	2,62
20	3,68	1,78	5	17,16	1,78	5	21,89	2,62
20	4,48	1,78	5	18,77	1,78	5	23,47	2,62
20	5,28	1,78	15	9,19	2,62	5	18,64	3,53
20	6,07	1,78	15	10,78	2,62	5	20,22	3,53
20	7,66	1,78	15	12,37	2,62	5	21,82	3,53
20	9,25	1,78	15	13,95	2,62	5	23,40	3,53
15	10,82	1,78	10	15,54	2,62	5	24,99	3,53
15	12,42	1,78	10	17,13	2,62	5	26,58	3,53
10	14,00	1,78	10	18,72	2,62	5	28,17	3,53

DISCOUNTS

Qty	1+	3+	5+
Disc.	Net	-5%	On request

Part N°	Material	Quantity per box	Price each 1 to 2
BOX-TOR-A	NBR 70 Sh A	340 o-rings	56,21 €

All dimensions in mm

Altri prodotti...



CHA_GC_145S
Cerniera a bandiera
inox, Ad avvitare



PARF80
Piede senza snodo,
Piede snodato
oscillante fissabile
Ø80



GBMz
Dado per vite a sfere,
Dado cilindrico a
circuiti multipli



DBL880
Rotella per catena,
Serie 880 e 881



MBF
Manicotto filettato di
bloccaggio, Montaggio
e regolazione rapidi



UGCG
Unità di guida per
cilindrico, Colonna di
guida



INS
Boccola autofilettante
acciaio, acciaio



BS3
Panamech, Multi-
Beam inox, Inox - con
vite a pressione



GB-RA
Ingranaggio dritto
ottone, Ottone
CuZn39Pb3



PWC
Inseri filettati, Kit
Powercoil - con o
senza attrezzo di posa



AC
Piastrina di riscontro,
13mm



QNJ
Cuscinetto a singola
corona di rulli
cilindrici, Anello
interno fiss...

Prodotti correlati



BOX-TOR-TOOL
Valigetta di
guarnizioni toriche in
nitrile, Extraction
tools