

Box set of Nitrile O-rings

BOX-TOR-A Diameters from 2.9x1.78mm to 28.17x3.53mm



- Assortment conforming to AS/BS standard
- 30 different sizes
- Material:
Nitrile NBR 70 Shore A
- Working temperature: -30 to +110°C

Uses

- Suitable for:
- Hydraulic oils
 - HFA fluids
 - HFB fluids
 - HFC fluids
 - Air

Info

- Ideal for the maintenance department

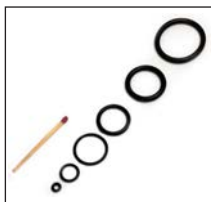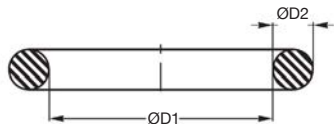

Box contents

Quantity	ØD1	ØD2
20	2,90	1,78
20	3,68	1,78
20	4,48	1,78
20	5,28	1,78
20	6,07	1,78
20	7,66	1,78
20	9,25	1,78
15	10,82	1,78
15	12,42	1,78
10	14,00	1,78

Quantity	ØD1	ØD2
10	15,60	1,78
5	17,16	1,78
5	18,77	1,78
15	9,19	2,62
15	10,78	2,62
15	12,37	2,62
15	13,95	2,62
10	15,54	2,62
10	17,13	2,62
10	18,72	2,62

Quantity	ØD1	ØD2
5	20,29	2,62
5	21,89	2,62
5	23,47	2,62
5	18,64	3,53
5	20,22	3,53
5	21,82	3,53
5	23,40	3,53
5	24,99	3,53
5	26,58	3,53
5	28,17	3,53

DISCOUNTS

Qty	1+	3+	5+
Disc.	Net	-5%	On request

Part N°	Material	Quantity per box	Price each 1 to 2
BOX-TOR-A	NBR 70 Sh A	340 o-rings	56,21 €

All dimensions in mm

Altri prodotti...



Accessori per ventosa,
Adattatore per inserto



Riduttore a ruota e
vite senza fine, fino a
5 Nm



Contenitore a becco,
8mm




Riduttore a ruota e
vite senza fine, Albero
semplice in uscita per
r...



Rullo folle plastica,
PVC



Spazzola cilindrica
modulare, Filo
poliestere PBT

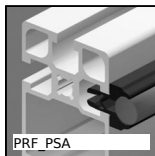

Rotella per profilo
alluminio, Supporto
d'albero



Ingranaggio dritto
acciaio, Acciaio
20NCD2



Pignone tendicatena,
Per ambienti
aggressivi



Sistema di chiusura
per profili alluminio,
Serratura doppia



Piede fisso,
Antivibrante



Small dimension latch
with locking system,
Aluminium

Prodotti correlati



Valigetta di
guarnizioni toriche in
nitrile, Extraction
tools