

# Box set of Nitrile O-rings

## BOX-TOR-A Diameters from 2.9x1.78mm to 28.17x3.53mm



- Assortment conforming to AS/BS standard
- 30 different sizes
- Material:  
Nitrile NBR 70 Shore A
- Working temperature: -30 to +110°C

### Uses

- Suitable for:
- Hydraulic oils
  - HFA fluids
  - HFB fluids
  - HFC fluids
  - Air

### Info

- Ideal for the maintenance department

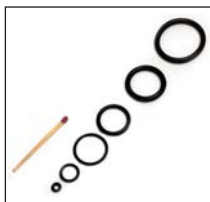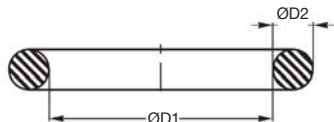

### Box contents

Quantity	ØD1	ØD2	Quantity	ØD1	ØD2	Quantity	ØD1	ØD2
20	2,90	1,78	10	15,60	1,78	5	20,29	2,62
20	3,68	1,78	5	17,16	1,78	5	21,89	2,62
20	4,48	1,78	5	18,77	1,78	5	23,47	2,62
20	5,28	1,78	15	9,19	2,62	5	18,64	3,53
20	6,07	1,78	15	10,78	2,62	5	20,22	3,53
20	7,66	1,78	15	12,37	2,62	5	21,82	3,53
20	9,25	1,78	15	13,95	2,62	5	23,40	3,53
15	10,82	1,78	10	15,54	2,62	5	24,99	3,53
15	12,42	1,78	10	17,13	2,62	5	26,58	3,53
10	14,00	1,78	10	18,72	2,62	5	28,17	3,53

### DISCOUNTS

Qty	1+	3+	5+
Disc.	Net	-5%	On request

Part N°	Material	Quantity per box	Price each 1 to 2
BOX-TOR-A	NBR 70 Sh A	340 o-rings	56,21 €

All dimensions in mm

## Altri prodotti...



CHMR30

Riduttore a ruota e vite senza fine, fino a 28 Nm



MAX2

Motoriduttore DC 12V e 24V DC, da 0,07 a 0,2Nm



CNA-CNG

Staffa di montaggio per molla a gas, Staffa di montaggio a squadra p...



YG2

Ingranaggio dritto PRESTAZIONE, Acciaio 35NCD6



SVR20

Martinetto a vite - Vite rotante, Con madrevite esterna



VTAP

Vite a testa magnetica, Con rivestimento in gomma



T5P\_T10P

Piastra di giunzione per cinghia T, T10



ZDB

Ingranaggio conico in plastica, 2:1



F7-I

Visualizzatore multifunzione, Con sensore di posizione



CHA\_GC\_9SS

Cerniera a bandiera inox, A saldare



GTCSS

Rullo tendcinghia, Per ambienti aggressivi



GLP

Volantino a 6 lobi filettato, Tecnopolimero - Inox

## Prodotti correlati



BOX-TOR-TOOL

Valigetta di guarnizioni toriche in nitrile, Extraction tools