

Box set of Nitrile O-rings

Diameters 20,38x1,78mm to 50,16x5,34mm **BOX-TOR-B**

- Assortment conforming to AS/BS standard
- 24 different sizes
- Material:
Nitrile NBR 70 Shore A
- Working temperature: -30 to +110°C



Uses

Suitable for:

- Hydraulic oils
- HFA fluids
- HFB fluids
- HFC fluids
- Air

Info

- Ideal for the maintenance department

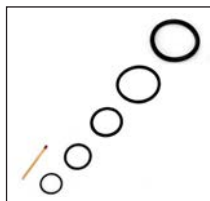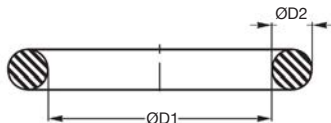

Box contents

Quantity	ØD1	ØD2
15	20,35	1,78
15	21,95	1,78
15	25,07	2,62
15	26,64	2,62
15	28,25	2,62
15	29,82	2,62
10	31,42	2,62
10	33,00	2,62
10	34,59	2,62
15	29,75	3,53
15	31,34	3,53
15	32,92	3,53

Quantity	ØD1	ØD2
10	34,52	3,53
10	36,10	3,53
10	37,69	3,53
10	40,87	3,53
10	44,04	3,53
10	47,22	5,53
10	50,40	3,53
10	37,47	5,34
10	40,65	5,34
10	43,82	5,34
5	47,00	5,34
5	50,16	5,34

DISCOUNTS

Qty	1+	3+	5+
Disc.	Net	-5%	On request

Part N°	Material	Quantity per box	Price each 1 to 2
BOX-TOR-B	NBR 70 Sh A	275 o-rings	104,60 €

All dimensions in mm

0 825 88 6000
Service 0,15 € / min
+ prix appel

Fax

Altri prodotti...



NJM
Connettore rinvio
d'angolo, Multiplo



WING
Dado ad alette per
serraggio manuale,
Inox DIN 314/315



SUA4_L
Giunzione per catena
al metro, Falsa maglia
- acciaio



MPB
Distanziatore
esagonale, Ottone



VAP
Magnete con foro
centrale, Con foro
centrale



EHD08-9
Riduttore coassiale,
da 35 a 50 Nm




G2
Ingranaggio dritto
acciaio, Acciaio
20NCD2



SLB
Pistoncino a molla,
acciaio classe 5.8




PF30NM
Riduttore a ruota e
vite senza fine, fino a
8.8 Nm

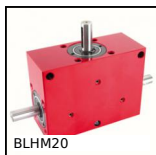

BLHM20
Rinvio angolare, fino a
1.77 Nm



PHTss
Maniglia a ponte, Fino
a 250°C

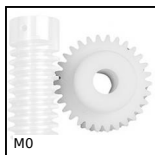

M0
Coppia ruota e vite
senza fine, Plastica
lavorata (delrin)

Prodotti correlati



BOX-TOR-TOOL
Valigetta di
guarnizioni toriche in
nitrile, Extraction
tools