

Box set of Nitrile O-rings

Diameters 20,38x1,78mm to 50,16x5,34mm **BOX-TOR-B**

- Assortment conforming to AS/BS standard
- 24 different sizes
- Material:
Nitrile NBR 70 Shore A
- Working temperature: -30 to +110°C



Uses

Suitable for:

- Hydraulic oils
- HFA fluids
- HFB fluids
- HFC fluids
- Air

Info

- Ideal for the maintenance department

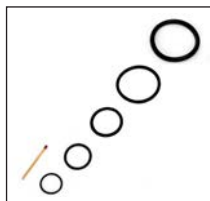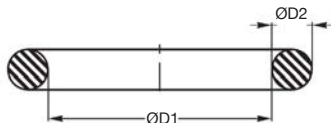

Box contents

Quantity	ØD1	ØD2
15	20,35	1,78
15	21,95	1,78
15	25,07	2,62
15	26,64	2,62
15	28,25	2,62
15	29,82	2,62
10	31,42	2,62
10	33,00	2,62
10	34,59	2,62
15	29,75	3,53
15	31,34	3,53
15	32,92	3,53

Quantity	ØD1	ØD2
10	34,52	3,53
10	36,10	3,53
10	37,69	3,53
10	40,87	3,53
10	44,04	3,53
10	47,22	5,53
10	50,40	3,53
10	37,47	5,34
10	40,65	5,34
10	43,82	5,34
5	47,00	5,34
5	50,16	5,34

DISCOUNTS

Qty	1+	3+	5+
Disc.	Net	-5%	On request

Part N°	Material	Quantity per box	Price each 1 to 2
BOX-TOR-B	NBR 70 Sh A	275 o-rings	104,60 €

All dimensions in mm

0 825 88 6000
Service 0,15 € / min
+ prix appel

Fax

cial2@hpceurope.com

HPC

SUPPLEMENT 2019

213

Altri prodotti...



AC

Pastrina di riscontro,
15mm



CHMX_CHMDX

Albero per riduttore a
ruota e vite senza fine
CHMR e CHM, Albero
se...



G0

Ingranaggio dritto
acciaio, Acciaio
20NCD2



BPPE

Sfera portante,
Leggero




PRES

Accessori per pressa
PRES-3HR e
PRES-4HR, Portapinzine



HLUss

Volantino a razze,
Inox 316

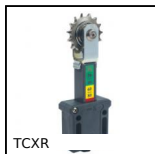


TCXR

Tenditore per catena
automatico, Con
pignone acciaio



NCT

Giunto di
collegamento, Ad
angolo fisso

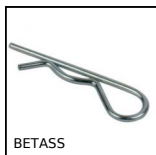

BETASS

Copiglia beta, Beta



PSPT

Manopola a pressione,
PVC



RBNtc

Ruota girevole a foro
centrale, Acciaio -
caucciù - a doppio



PCS50K

Pignone a catena
dentatura temprata,
12.7mm (DIN08B-1)

Prodotti correlati



BOX-TOR-TOOL

Valigetta di
guarnizioni toriche in
nitrile, Extraction
tools