

# Box set of Nitrile O-rings

Diameters 20,38x1,78mm to 50,16x5,34mm **BOX-TOR-B**

- Assortment conforming to AS/BS standard
- 24 different sizes
- Material:  
Nitrile NBR 70 Shore A
- Working temperature: -30 to +110°C



## Uses

Suitable for:

- Hydraulic oils
- HFA fluids
- HFB fluids
- HFC fluids
- Air

## Info

- Ideal for the maintenance department

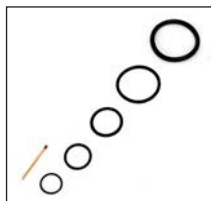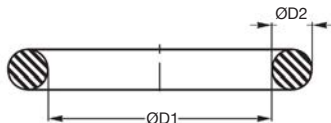

## Box contents

Quantity	ØD1	ØD2
15	20,35	1,78
15	21,95	1,78
15	25,07	2,62
15	26,64	2,62
15	28,25	2,62
15	29,82	2,62
10	31,42	2,62
10	33,00	2,62
10	34,59	2,62
15	29,75	3,53
15	31,34	3,53
15	32,92	3,53

Quantity	ØD1	ØD2
10	34,52	3,53
10	36,10	3,53
10	37,69	3,53
10	40,87	3,53
10	44,04	3,53
10	47,22	5,53
10	50,40	3,53
10	37,47	5,34
10	40,65	5,34
10	43,82	5,34
5	47,00	5,34
5	50,16	5,34

## DISCOUNTS

Qty	1+	3+	5+
Disc.	Net	-5%	On request

Part N°	Material	Quantity per box	Price each 1 to 2
BOX-TOR-B	NBR 70 Sh A	275 o-rings	104,60 €

All dimensions in mm

**0 825 88 6000**  
Service 0,15 € / min  
+ prix appel

Fax


## Altri prodotti...



H3  
Ingranaggio elicoidale ad assi incrociati a 90°, Plastica lavorata



PSEC  
Maniglia a ponte di sicurezza, Termoplastica

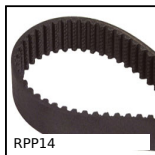

RPP14  
Cinghia di trasmissione RPP, RPP14



CHA\_GC\_14SS  
Cerniera a bandiera inox, Ad avvitare




HBM  
Guida su semi-binari, Boccola di regolazione



SH0  
Ingranaggio elicoidale ad assi paralleli, Acciaio 20NCD2



UTKpwr  
Guida lineare Utilitrack®, Carrello a rotelle - rivestimento polimero

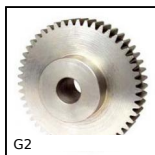

G2  
Ingranaggio dritto acciaio, Acciaio 20NCD2



BAG0  
Anello di bloccaggio, Inox



HTD5M\_15  
Puleggia dentata di trasmissione tipo



VQTplqn  
Chiusura ¼ di giro - Piastra di bloccaggio,



WJUM16  
Pattino Drylin® W, Pattino

## Prodotti correlati



BOX-TOR-TOOL  
Valigetta di guarnizioni toriche in nitrile, Extraction tools