

Box set of Nitrile O-rings

Diameters 20,38x1,78mm to 50,16x5,34mm **BOX-TOR-B**

- Assortment conforming to AS/BS standard
- 24 different sizes
- Material:
Nitrile NBR 70 Shore A
- Working temperature: -30 to +110°C



Uses

Suitable for:

- Hydraulic oils
- HFA fluids
- HFB fluids
- HFC fluids
- Air

Info

- Ideal for the maintenance department

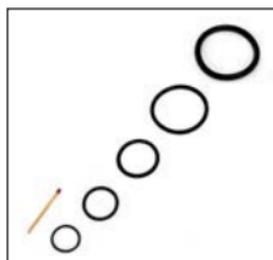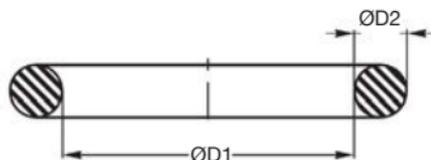

Box contents

Quantity	ØD1	ØD2
15	20,35	1,78
15	21,95	1,78
15	25,07	2,62
15	26,64	2,62
15	28,25	2,62
15	29,82	2,62
10	31,42	2,62
10	33,00	2,62
10	34,59	2,62
15	29,75	3,53
15	31,34	3,53
15	32,92	3,53

Quantity	ØD1	ØD2
10	34,52	3,53
10	36,10	3,53
10	37,69	3,53
10	40,87	3,53
10	44,04	3,53
10	47,22	5,53
10	50,40	3,53
10	37,47	5,34
10	40,65	5,34
10	43,82	5,34
5	47,00	5,34
5	50,16	5,34

DISCOUNTS

Qty	1+	3+	5+
Disc.	Net	-5%	On request

Part N°	Material	Quantity per box	Price each 1 to 2
BOX-TOR-B	NBR 70 Sh A	275 o-rings	104,60 €

All dimensions in mm

0 825 88 6000

Service 0,15 € / min
+ prix appel

Fax

cial2@hpceurope.com

HPC

SUPPLEMENT 2019

213

Altri prodotti...



PNA

Giunto elastico
PERIFLEX®, Giunto
completo



KS

Chiavetta in barre,
Acciaio - in barre



PRF_GAL

Rotella per profilo
alluminio, Kit di
fissaggio per rotella
eccentrica



EKGS

Giunto senza gioco
Gerwah®, da 0.5 a
35Nm



PP60

Riduttore a ruota e
vite senza fine, da
17.80 a 34 Nm



GP

Chiusura a leva molla
a trazione
compensata, Con
porta-lucchetto



PF30NM

Riduttore a ruota e
vite senza fine, fino a
8.8 Nm



PW_PWG05

Ruota di precisione,
Bronzo



RAG

Guida di scorrimento
a rullini,



RAG-12-M8

Guida di scorrimento
a rotelle, Sistema di
ancoraggio



IN1

Ingranaggio interno,
Acciaio 20NCD2



DOMI120

Slitta di regolazione
Domino 120, Slitta
DOMILINE 120 con
contatore ...

Prodotti correlati



BOX-TOR-TOOL

Valigetta di
guarnizioni toriche in
nitrile, Extraction
tools