

# Box set of Nitrile O-rings

Diameters 18,00x2,00mm à 50,00x5,00mm **BOX-TOR-D**

- Assortment conforming to AS/BS standard
- 24 different sizes
- Material:  
Nitrile NBR 70 Shore A
- Working temperature: -30 to +110°C



## Uses

Suitable for:

- Hydraulic oils
- HFA fluids
- HFB fluids
- HFC fluids
- Air

## Info

- Ideal for the maintenance department

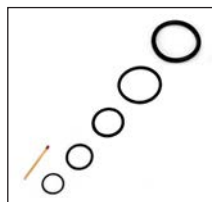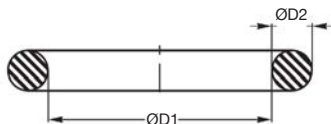

## Box contents

Quantity	ØD1	ØD2
15	18,00	2,00
15	20,00	2,00
15	22,00	2,00
15	25,00	2,00
15	28,20	3,00
15	30,20	3,00
10	32,20	3,00
10	26,20	3,00
15	25,00	4,00
15	30,00	4,00
15	32,00	4,00
15	34,00	4,00

Quantity	ØD1	ØD2
15	36,00	4,00
10	38,00	4,00
10	10,00	4,00
10	44,00	4,00
10	48,00	4,00
10	50,00	4,00
10	25,00	5,00
10	30,00	5,00
10	35,00	5,00
10	40,00	5,00
5	45,00	5,00
5	50,00	5,00

## DISCOUNTS

Qty	1+	3+	5+
Disc.	Net	-5%	On request

Part N°	Material	Quantity per box	Price each 1 to 2
BOX-TOR-D	NBR 70 Sh A	285 o-rings	106,37 €

All dimensions in mm

**0 825 88 6000**  
Service 0,15 € / min  
+ prix appel

Fax

## Altri prodotti...



TCSH

Tenditore per catena automatico, Con pattino



DB

Ingranaggio conico in acciaio, 2:1



T5\_11

Puleggia dentata di posizionamento tipo T, T5 alluminio



LVT

Mini martinetto motorizzato 2A, 2 ampere



CFF\_SS

Testa a snodo femmina DIN ISO12240-4, Inox / bronzo - Serie



DFG

Ventosa, nitrile



FRtool

Attrezzi per inserti filettati, Attrezzo di posa



MFBS

Giunto a soffietto Inox, Inox - con vite a pressione



G4

Ingranaggio dritto acciaio, Acciaio



SHS

Vite a spalla inox 303, Inox 303



DOG111

Motoriduttore DC 12V e 24V DC, da 1.5 a 6



FF40

Riduttore ad alberi paralleli, da 59 a 210

## Prodotti correlati



BOX-TOR-TOOL

Valigetta di guarnizioni toriche in nitrile, Extraction tools