

# Box set of Nitrile O-rings

Diameters 18,00x2,00mm à 50,00x5,00mm **BOX-TOR-D**

- Assortment conforming to AS/BS standard
- 24 different sizes
- Material:  
Nitrile NBR 70 Shore A
- Working temperature: -30 to +110°C



## Uses

Suitable for:

- Hydraulic oils
- HFA fluids
- HFB fluids
- HFC fluids
- Air

## Info

- Ideal for the maintenance department

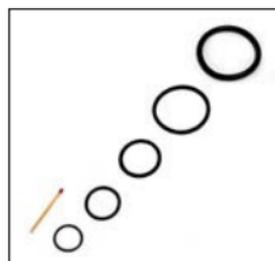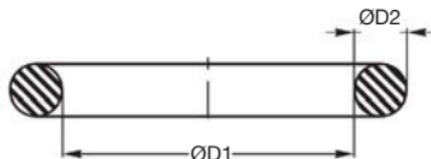

## Box contents

Quantity	ØD1	ØD2
15	18,00	2,00
15	20,00	2,00
15	22,00	2,00
15	25,00	2,00
15	28,20	3,00
15	30,20	3,00
10	32,20	3,00
10	26,20	3,00
15	25,00	4,00
15	30,00	4,00
15	32,00	4,00
15	34,00	4,00

Quantity	ØD1	ØD2
15	36,00	4,00
10	38,00	4,00
10	10,00	4,00
10	44,00	4,00
10	48,00	4,00
10	50,00	4,00
10	25,00	5,00
10	30,00	5,00
10	35,00	5,00
10	40,00	5,00
5	45,00	5,00
5	50,00	5,00

## DISCOUNTS

Qty	1+	3+	5+
Disc.	Net	-5%	On request

Part N°	Material	Quantity per box	Price each 1 to 2
BOX-TOR-D	NBR 70 Sh A	285 o-rings	106,37 €

All dimensions in mm

**0 825 88 6000**  
Service 0,15 € / min  
+ prix appel

Fax

cial2@hpceurope.com

**HPC**

SUPPLEMENT 2019

215

## Altri prodotti...



TB8

Cuscinetto assiale a rulli cilindrici, Acciaio



SEH

Attrezzo di bloccaggio a tirante, A tirante - inox



LRRA

Latch with locking system, Aluminium



RVM14

Riduttore manuale, A ruota e vite senza fine



CHML63

Riduttore a ruota e vite senza fine, fino a 138 Nm - Con limitatore ...



HBM

Guida su semi-binari, Boccola di regolazione



HRV

Sistema di guida su binario a V Simple Select®, Binario con carrello



DUPss

Calettatore di bloccaggio autocentrante inox, Senza ghiera



SLB

Pistoncino a molla, inox



AT5-BAR

Barra dentata, AT5



T10courroie

Cinghia di posizionamento T, T10 Poliuretano



DTR

Pignone tendicatenata, Ruota dentata in plastica

## Prodotti correlati



BOX-TOR-TOOL

Valigetta di guarnizioni toriche in nitrile, Extraction tools