

Box set of Nitrile O-rings

Diameters 18,00x2,00mm à 50,00x5,00mm **BOX-TOR-D**

- Assortment conforming to AS/BS standard
- 24 different sizes
- Material:
Nitrile NBR 70 Shore A
- Working temperature: -30 to +110°C



Uses

Suitable for:

- Hydraulic oils
- HFA fluids
- HFB fluids
- HFC fluids
- Air

Info

- Ideal for the maintenance department

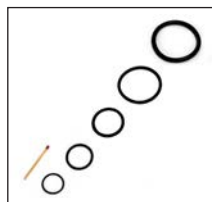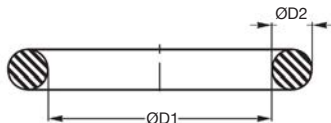

Box contents

Quantity	ØD1	ØD2
15	18,00	2,00
15	20,00	2,00
15	22,00	2,00
15	25,00	2,00
15	28,20	3,00
15	30,20	3,00
10	32,20	3,00
10	26,20	3,00
15	25,00	4,00
15	30,00	4,00
15	32,00	4,00
15	34,00	4,00

Quantity	ØD1	ØD2
15	36,00	4,00
10	38,00	4,00
10	10,00	4,00
10	44,00	4,00
10	48,00	4,00
10	50,00	4,00
10	25,00	5,00
10	30,00	5,00
10	35,00	5,00
10	40,00	5,00
5	45,00	5,00
5	50,00	5,00

DISCOUNTS

Qty	1+	3+	5+
Disc.	Net	-5%	On request


Part N°	Material	Quantity per box	Price each 1 to 2
BOX-TOR-D	NBR 70 Sh A	285 o-rings	106,37 €

All dimensions in mm

0 825 88 6000
Service 0,15 € / min
+ prix appel

Fax

Altri prodotti...

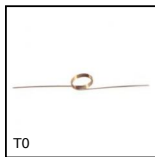


T0

Molla di torsione, Inox



AC156-157

Riscontro per chiusura a leva rigida ad anello, 25.5mm

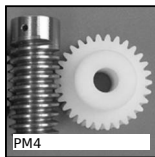

PM4

Coppia ruota e vite senza fine, Plastica lavorata (delrin)



ACLAPA

Sistema di chiusura, Battuta a calamita



NSU

Supporto per sensore, Morsetto universale base a 90°



PITA

Pistoncino a molla, con maniglia a T



GLP

Volantino a 6 lobi, Tecnopolimero - Acciaio



PF30

Riduttore a ruota e vite senza fine, fino a 8.80 Nm



EIM

Cavalletto Inox, Inox



DB

Ingranaggio conico - Acciaio 60C40, 2:1



PW_PWG2

Vite senza fine di precisione, Inox



MHSC

Giunto flessibile a disco semplice, Disco semplice

Prodotti correlati



BOX-TOR-TOOL

Valigetta di guarnizioni toriche in nitrile, Extraction tools