

D-Ring Kit, NBR Shore A

Flange seals

BOX-TOR-DRING

- Selection of D-Ring flange seals
- 9 sizes
- Material:
Nitrile NBR 90 shore A
- Working temperature range: -30° to +110°C

Applications

Suitable for:


- Hydraulic fluids
- HFA fluids
- HFB fluids
- HFC fluids

Advantages

- Good extrusion resistance
- Long service life
- Easy to assemble as the seal will adhere to the flange
- Good resistance to vibration and low temperatures


Info

- Ideal for use in the maintenance dept

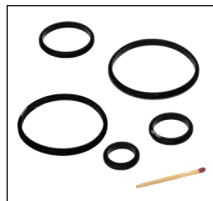

Box contents

Quantity	ØA	B	H
10	18,90	3,40	4,95
10	25,25	3,40	4,95
10	31,60	3,40	4,95
10	37,95	3,40	4,95
10	44,37	3,40	4,95
10	50,72	3,40	4,95
10	54,20	3,40	4,95
5	57,07	3,40	4,95
5	63,42	3,40	4,95

 

DISCOUNTS

Qty	1+	3+	5+
Disc.	Net	-5%	On request

Part N°	Material	Qty per box	Price each 1 to 2
BOX-TOR-DRING	NBR 90 Sh A	80 pieces	202,15 €

All dimensions in mm

0 825 88 6000
Service 0,15 € / min
+ prix appel

Fax

cial2@hpceurope.com

HPC

SUPPLEMENT 2019

221

Altri prodotti...



RT25
Calettatore di bloccaggio, Coppia media/elevata



RJA00_28
Guarnizione in gomma, Da agganciare



BAN
Connettore / supporto per profili alluminio, Regolabile



EFTC
Supporto di fissaggio, Inox



PX
Riduttore a ruota e vite senza fine, Albero semplice in uscita per r...



ALIDRP240
Alimentazione, 10 A



SBS_M
Catena semplice al metro, Inox




LQT
Chiusura a sfera, Chiusura rapida



PW_PWG25
Vite senza fine di precisione, Acciaio



PRF19_E
Squadra di giunzione, PRF19 a PRF32

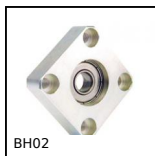

BH02
Cuscinetto radiale flangiato, Montaggio con circlips



PP35
Riduttore a ruota e vite senza fine, da 2.20 a 4.10 Nm

Prodotti correlati



BOX-TOR-TOOL
Valigetta di guarnizioni toriche in nitrile, Extraction tools