

# D-Ring Kit, NBR Shore A

## Flange seals

## BOX-TOR-DRING

- Selection of D-Ring flange seals
- 9 sizes
- Material:  
Nitrile NBR 90 shore A
- Working temperature range: -30° to +110°C

### Applications

Suitable for:


- Hydraulic fluids
- HFA fluids
- HFB fluids
- HFC fluids

### Advantages

- Good extrusion resistance
- Long service life
- Easy to assemble as the seal will adhere to the flange
- Good resistance to vibration and low temperatures


### Info

- Ideal for use in the maintenance dept

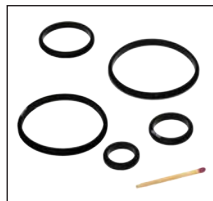

### Box contents

 Quantity	ØA	B	H
10	18,90	3,40	4,95
10	25,25	3,40	4,95
10	31,60	3,40	4,95
10	37,95	3,40	4,95
10	44,37	3,40	4,95
10	50,72	3,40	4,95
10	54,20	3,40	4,95
5	57,07	3,40	4,95
5	63,42	3,40	4,95



### DISCOUNTS

Qty	1+	3+	5+
Disc.	Net	-5%	On request

Part N°	Material	Qty per box	Price each 1 to 2
BOX-TOR-DRING	NBR 90 Sh A	80 pieces	202,15 €

All dimensions in mm

**0 825 88 6000**  
Service 0,15 € / min  
+ prix appel

Fax

cial2@hpceurope.com

**HPC**

SUPPLEMENT 2019

221

## Altri prodotti...



PSPD40

Manopola a pressione,  
PVC nero




BPPss

Supporto ritto in  
lamiera con  
cuscinetto inox, Inox



BOX-CSss

Fascette di serraggio,  
Valigetta di fascette  
inox

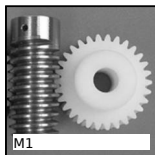

M1

Coppia ruota e vite  
senza fine, Plastica  
lavorata (delrin)




PAT85

Piede snodato con  
base stampata Ø85, Ø  
85



G01

Giunto cardanico  
semplice,  
Sollecitazioni normale

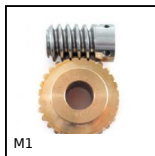

M1

Coppia ruota e vite  
senza fine, Bronzo



SH1

Ingranaggio elicoidale  
ad assi paralleli,  
Acciaio 20NCD2



CHMR63

Riduttore a ruota e  
vite senza fine, fino a  
3000



RPCtc

Ruota girevole a foro  
centrale, Acciaio -  
20NCD2



ACLRP

Rullo per profilati, Con  
cuscinetto a sfere



BFA

Anelli d'arresto per  
alberi, Anello tipo E

## Prodotti correlati



BOX-TOR-TOOL

Valigetta di  
guarnizioni toriche in  
nitrile, Extraction  
tools