

# D-Ring Kit, NBR Shore A

## Flange seals

## BOX-TOR-DRING

- Selection of D-Ring flange seals
- 9 sizes
- Material:  
Nitrile NBR 90 shore A
- Working temperature range: -30° to +110°C

### Applications


- Suitable for:
- Hydraulic fluids
  - HFA fluids
  - HFB fluids
  - HFC fluids

### Advantages

- Good extrusion resistance
- Long service life
- Easy to assemble as the seal will adhere to the flange
- Good resistance to vibration and low temperatures


### Info

- Ideal for use in the maintenance dept

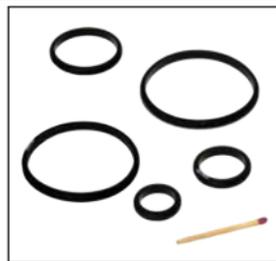

### Box contents

Quantity	ØA	B	H
10	18,90	3,40	4,95
10	25,25	3,40	4,95
10	31,60	3,40	4,95
10	37,95	3,40	4,95
10	44,37	3,40	4,95
10	50,72	3,40	4,95
10	54,20	3,40	4,95
5	57,07	3,40	4,95
5	63,42	3,40	4,95

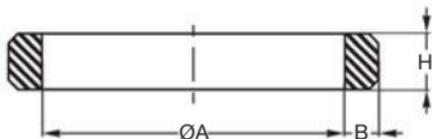

### DISCOUNTS

Qty	1+	3+	5+
Disc.	Net	-5%	On request

Part N°	Material	Qty per box	Price each 1 to 2
BOX-TOR-DRING	NBR 90 Sh A	80 pieces	202,15 €

All dimensions in mm

0 825 88 6000

Service 0,15 € / min  
+ prix appel

Fax

cial2@hpceurope.com

HPC

SUPPLEMENT 2019

221

## Altri prodotti...



SC2

Giunto rigido in 2 parti, Ganascia di serraggio



TBD

Tavola di posizionamento a passo inverso manuale, 2kg



BLM

Pressore liscio a molla, Corpo termoplastica



RBGpl

Ruota fissa con piastra, Acciaio - gomma grigia



FF20

Riduttore ad alberi paralleli, da 5.80 a 23 Nm



PRF4590

Profilato alluminio standard, 45 x 90 mm



VAP

Magnete con foro centrale, Con foro centrale



G3-ECO

Ingranaggio dritto acciaio - serie ECO, Acciaio C45



HFL

Ruota libera, Combinata ad aghi



VTAP

Vite a testa magnetica, Con



BHC

Vite a testa bombata BHC , Inox A2



ACM\_TRI

Tirante chiusura in gomma, Caucciù

## Prodotti correlati



BOX-TOR-TOOL

Valigetta di guarnizioni toriche in nitrile, Extraction tools