

Nitrile O-ring kit


BOX-TOR-MAX Sizes from 2.9x1.78mm to 82.14x3.53mm

- 5 different boxes containing AS/BS standards in
- 78 sizes
- Material:
Nitrile NBR 90 shore A
- Working temperature range: -30° to +110°C

Applications

Suitable for:

- Hydraulic fluids
- HFA fluids
- HFB fluids
- HFC fluids
- Air

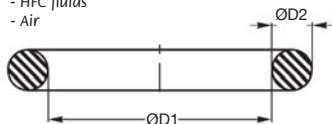

Kit contents:

Box 1:30 O-rings in 5 sizes

Quantity	ØD1	ØD2
8	24,99	3,53
8	32,92	3,53
6	37,69	3,53
4	47,22	3,53
4	56,74	3,53

Box 2:127 O-rings for BOSS fittings in 6 sizes

Quantité	ØD1	ØD2
25	8,92	1,83
25	11,89	1,98
25	16,36	2,21
25	19,18	2,46
16	23,47	2,95
11	29,74	2,95

Box 3:485 1.78mm O-rings in 24 sizes

Quantity	ØD1	ØD2	Quantity	ØD1	ØD2
25	2,90	1,78	25	18,77	1,78
25	3,68	1,78	20	20,35	1,78
25	4,47	1,78	20	21,95	1,78
25	5,28	1,78	20	23,52	1,78
25	6,07	1,78	15	25,12	1,78
25	7,65	1,78	15	26,70	1,78
25	9,25	1,78	15	28,30	1,78
25	10,82	1,78	15	29,87	1,78
25	12,42	1,78	15	31,47	1,78
25	14,00	1,78	15	34,65	1,78
25	15,60	1,78	10	37,82	1,78
25	17,17	1,78	10	41,00	1,78

Dimensions en mm

BOX-TOR-MAX



Box 4:440 2.62mm

O-rings in 24 sizes

Quantité	ØD1	ØD2	Quantité	ØD1	ØD2
25	7,59	2,62	15	26,64	2,62
25	9,19	2,62	15	28,24	2,62
25	10,77	2,62	15	29,82	2,62
25	12,37	2,62	15	31,42	2,62
25	13,94	2,62	15	32,99	2,62
25	15,54	2,62	15	34,59	2,62
25	17,12	2,62	15	36,17	2,62
25	18,72	2,62	10	37,77	2,62
25	20,30	2,62	10	39,34	2,62
25	21,89	2,62	10	42,52	2,62
20	23,47	2,62	10	45,69	2,62
20	25,07	2,62	5	48,90	2,62

Box 5:285 3.53mm

O-rings in 19 sizes

Quantité	ØD1	ØD2	Quantité	ØD1	ØD2
20	18,64	3,53	14	34,52	3,53
20	20,22	3,53	14	36,09	3,53
20	21,82	3,53	13	37,69	3,53
20	23,39	3,53	12	40,87	3,53
20	24,99	3,53	12	44,04	3,53
16	26,57	3,53	10	50,39	3,53
16	28,17	3,53	10	56,74	3,53
16	29,74	3,53	10	69,44	3,53
16	31,34	3,53	10	82,14	3,53
16	32,92	3,53			



DISCOUNTS

Qty	1+	3+	5+
Disc.	Net	-5%	On request

Part N°	Material	Qty per box	Price each
BOX-TOR-MAX	NBR 90 Sh A	1415 pièces	1 to 2 197,33 €

Dimensions mm

0 825 88 6000

Service 0,15 € / min
+ prix appel

Fax

cial2@hpceurope.com

HPC

SUPPLEMENT 2019

219

Altri prodotti...




GMK17_R

Guida prodotto laterale tonda, Per imbottigliamento e imballaggio



PSPD18

Manopola a pressione, PVC nero

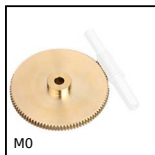

M0

Ruote per viti senza fine , Bronzo




BABM

Perno autobloccante con segmenti filettati, Acciaio



BABss

Perno autobloccante inox 303, Inox 303

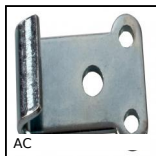

AC

Piastrina di riscontro, 15mm



BPL

Sfera portante con flangia, Leggero



SSG1

Ingranaggio dritto Inox, Inox 304L



ZBRA

Ingranaggio conico in plastica, 1:1



SHN

Dado esagonale - DIN934, Acciaio (Class 6|8)



BAG

Anello di bloccaggio in acciaio, Acciaio



PP50

Riduttore a ruota e vite senza fine, da 6.50 a 12.80 Nm

Prodotti correlati