

# Nitrile O-ring kit


## BOX-TOR-MAX Sizes from 2.9x1.78mm to 82.14x3.53mm

- 5 different boxes containing AS/BS standards in
- 78 sizes
- Material:  
Nitrile NBR 90 shore A
- Working temperature range: -30° to +110°C

### Applications

Suitable for:

- Hydraulic fluids
- HFA fluids
- HFB fluids
- HFC fluids
- Air

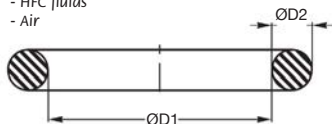

Kit contents:

#### Box 1:30 O-rings in 5 sizes

Quantity	ØD1	ØD2
8	24,99	3,53
8	32,92	3,53
6	37,69	3,53
4	47,22	3,53
4	56,74	3,53

#### Box 2:127 O-rings for BOSS fittings in 6 sizes

Quantité	ØD1	ØD2
25	8,92	1,83
25	11,89	1,98
25	16,36	2,21
25	19,18	2,46
16	23,47	2,95
11	29,74	2,95

#### Box 3:485 1.78mm O-rings in 24 sizes

Quantity	ØD1	ØD2	Quantity	ØD1	ØD2
25	2,90	1,78	25	18,77	1,78
25	3,68	1,78	20	20,35	1,78
25	4,47	1,78	20	21,95	1,78
25	5,28	1,78	20	23,52	1,78
25	6,07	1,78	15	25,12	1,78
25	7,65	1,78	15	26,70	1,78
25	9,25	1,78	15	28,30	1,78
25	10,82	1,78	15	29,87	1,78
25	12,42	1,78	15	31,47	1,78
25	14,00	1,78	15	34,65	1,78
25	15,60	1,78	10	37,82	1,78
25	17,17	1,78	10	41,00	1,78

Dimensions en mm

# BOX-TOR-MAX



## Box 4:440 2.62mm

### O-rings in 24 sizes

Quantité	ØD1	ØD2	Quantité	ØD1	ØD2
25	7,59	2,62	15	26,64	2,62
25	9,19	2,62	15	28,24	2,62
25	10,77	2,62	15	29,82	2,62
25	12,37	2,62	15	31,42	2,62
25	13,94	2,62	15	32,99	2,62
25	15,54	2,62	15	34,59	2,62
25	17,12	2,62	15	36,17	2,62
25	18,72	2,62	10	37,77	2,62
25	20,30	2,62	10	39,34	2,62
25	21,89	2,62	10	42,52	2,62
20	23,47	2,62	10	45,69	2,62
20	25,07	2,62	5	48,90	2,62

## Box 5:285 3.53mm

### O-rings in 19 sizes

Quantité	ØD1	ØD2	Quantité	ØD1	ØD2
20	18,64	3,53	14	34,52	3,53
20	20,22	3,53	14	36,09	3,53
20	21,82	3,53	13	37,69	3,53
20	23,39	3,53	12	40,87	3,53
20	24,99	3,53	12	44,04	3,53
16	26,57	3,53	10	50,39	3,53
16	28,17	3,53	10	56,74	3,53
16	29,74	3,53	10	69,44	3,53
16	31,34	3,53	10	82,14	3,53
16	32,92	3,53			



## DISCOUNTS

Qty	1+	3+	5+
Disc.	Net	-5%	On request

Part N°	Material	Qty per box	Price each
BOX-TOR-MAX	NBR 90 Sh A	1415 pièces	1 to 2 197,33 €

Dimensions mm

0 825 88 6000

Service 0,15 € / min  
+ prix appel

Fax

cial2@hpceurope.com

HPC

SUPPLEMENT 2019

219

## Altri prodotti...



PRF\_CHA

Cerniera ad avvitare,  
Su facciata



PCLA\_M

Maniglia a ripresa -  
femmina, Plastica



DFG

Ventosa, silicone



HRV

Sistema di guida su  
binario a V Simple  
Select®, Binario con  
carrello



PFL

P-FLEX, Vite a  
pressione



MPE

Distanziatore  
esagonale, Acciaio



OP3\_14\_06

Accessorio per  
indicatori, Boccola di  
riduzione



NANO

Variatore di velocità  
3A, 3 A



PM3

Coppia ruota e vite  
senza fine, Bronzo



YG2

Ingranaggio dritto  
PRESTAZIONE, Acciaio  
35NCD6



PR105

Piede fissabile con  
snodo - poliammide, Ø  
103



BABPass

Perno autobloccante  
inox temprato ad  
anello, Con  
impugnatura ad  
anello

**Prodotti correlati**