

Nitrile O-ring kit


BOX-TOR-MAX Sizes from 2.9x1.78mm to 82.14x3.53mm

- 5 different boxes containing AS/BS standards in
- 78 sizes
- Material:
Nitrile NBR 90 shore A
- Working temperature range: -30° to +110°C

Applications

Suitable for:

- Hydraulic fluids
- HFA fluids
- HFB fluids
- HFC fluids
- Air

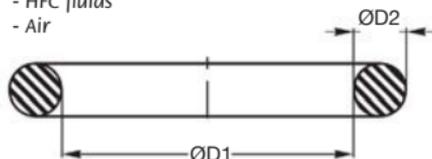

Kit contents:

Box 1:30 O-rings in 5 sizes

Quantity	ØD1	ØD2
8	24,99	3,53
8	32,92	3,53
6	37,69	3,53
4	47,22	3,53
4	56,74	3,53

Box 2:127 O-rings for BOSS fittings in 6 sizes

Quantité	ØD1	ØD2
25	8,92	1,83
25	11,89	1,98
25	16,36	2,21
25	19,18	2,46
16	23,47	2,95
11	29,74	2,95

Box 3:485 1.78mm O-rings in 24 sizes

Quantity	ØD1	ØD2	Quantity	ØD1	ØD2
25	2,90	1,78	25	18,77	1,78
25	3,68	1,78	20	20,35	1,78
25	4,47	1,78	20	21,95	1,78
25	5,28	1,78	20	23,52	1,78
25	6,07	1,78	15	25,12	1,78
25	7,65	1,78	15	26,70	1,78
25	9,25	1,78	15	28,30	1,78
25	10,82	1,78	15	29,87	1,78
25	12,42	1,78	15	31,47	1,78
25	14,00	1,78	15	34,65	1,78
25	15,60	1,78	10	37,82	1,78
25	17,17	1,78	10	41,00	1,78

Dimensions en mm

BOX-TOR-MAX



Box 4:440 2.62mm

O-rings in 24 sizes

Quantité	ØD1	ØD2	Quantité	ØD1	ØD2
25	7,59	2,62	15	26,64	2,62
25	9,19	2,62	15	28,24	2,62
25	10,77	2,62	15	29,82	2,62
25	12,37	2,62	15	31,42	2,62
25	13,94	2,62	15	32,99	2,62
25	15,54	2,62	15	34,59	2,62
25	17,12	2,62	15	36,17	2,62
25	18,72	2,62	10	37,77	2,62
25	20,30	2,62	10	39,34	2,62
25	21,89	2,62	10	42,52	2,62
20	23,47	2,62	10	45,69	2,62
20	25,07	2,62	5	48,90	2,62

Box 5:285 3.53mm

O-rings in 19 sizes

Quantité	ØD1	ØD2	Quantité	ØD1	ØD2
20	18,64	3,53	14	34,52	3,53
20	20,22	3,53	14	36,09	3,53
20	21,82	3,53	13	37,69	3,53
20	23,39	3,53	12	40,87	3,53
20	24,99	3,53	12	44,04	3,53
16	26,57	3,53	10	50,39	3,53
16	28,17	3,53	10	56,74	3,53
16	29,74	3,53	10	69,44	3,53
16	31,34	3,53	10	82,14	3,53
16	32,92	3,53			



DISCOUNTS

Qty	1+	3+	5+
Disc.	Net	-5%	On request

Part N°	Material	Qty per box	Price each
BOX-TOR-MAX	NBR 90 Sh A	1415 pièces	1 to 2 197,33 €

Dimensions mm

0 825 88 6000

Service 0,15 € / min
+ prix appel

Fax

cial2@hpceurope.com

HPC

SUPPLEMENT 2019


219

Altri prodotti...



TBD

Tavola di
posizionamento a
passo inverso
manuale, 20kg

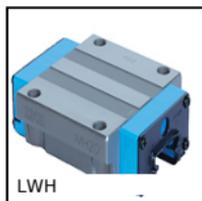

LWH

Guida lineare a sfere -
Sfere acciaio, Carello -
da 9320 N a 71300 N



M2

Vite senza fine,
Acciaio temprato



TFR

Tenditore rigido, Fisso



PDD

Pressore a molla
sensore di
rilevamento, Con asta
di comando per int...



NT63

Riduttore coassiale a
treni paralleli, da 8 to
20 Nm - a treni paral...




ADL

Anello di
sollevamento,
Femmina



ERC

Terminale rapido per
cavi, A occhio

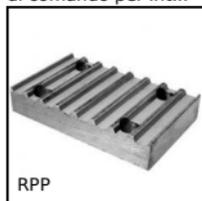

RPP

Piastra di giunzione
per cinghia RPP,



LC

Limitatore di coppia
ad attrito, 190 a 1800



HLUss

Volantino a razze,
Inox 316



ACLAPA

Sistema di chiusura,
Battuta a calamita

Prodotti correlati