

O-Ring kit, NBR90Sh A

BOX-TOR-ORFS Sizes from 7.65x 1.78mm to 37.82x1.78mm

- Selection of O-Rings for ORF fittings
- 8 sizes
- Material:
Nitrile NBR 90 shore A
- Working temperature range: -30° to +110°C


Applications

Suitable for:

- Hydraulic fluids
- HFA fluids
- HFB fluids
- HFC fluids
- Air

Info

- Ideal for use in the maintenance dept.

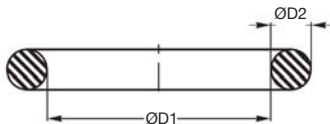

Box contents

Quantity	ØD1	ØD2
25	7,65	1,78
25	9,25	1,78
25	12,42	1,78
25	15,60	1,78
20	18,77	1,78
15	23,52	1,78
10	29,87	1,78
10	37,82	1,78

DISCOUNTS

Qty	1+	3+	5+
Disc.	Net	-5%	On request

Part N°	Material	Qty per box	Price each
BOX-TOR-ORFS	NBR 90 Sh A	155 pieces	35,77 €

All dimensions in mm

Altri prodotti...



SCR
Accessori per ventosa,
Inserto per ventosa -
Vite cava



PFC
Piede fisso,
Livellamento per
piccoli elementi



LRHSS
Vite trapezoidale a
doppia inclinazione, a
doppia inclinazione - 1
f...



NSR
Connettore rinvio
d'angolo, Regolabile



RFVcap
Coperchio di
protezione inox,
Coperchio di
protezione chiuso



PRF_ER
Elementi di giunzione,
Elemento di raccordo



M2
Vite senza fine,
Plastica lavorata
(delrin)



PTRSS
Pignone tendicatena,
Per ambienti
aggressivi




PTGP
Puleggia folle, Per
cinghia piatta



PRS80
Piede snodato tutto
inox Ø80, Ø 80



CLSCLP_SS
Perno serie corta inox,
Inox - serie corta

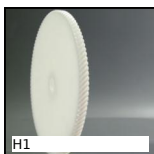

H1
Ingranaggio elicoidale
ad assi incrociati a
90°, Plastica lavorata
...

Prodotti correlati



BOX-TOR-TOOL
Valigetta di
guarnizioni toriche in
nitrile, Extraction
tools