

# O-Ring kit, NBR90Sh A

## BOX-TOR-ORFSizes from 7.65x 1.78mm to 37.82x1.78mm

- Selection of O-Rings for ORF fittings
- 8 sizes
- Material:  
Nitrile NBR 90 shore A
- Working temperature range: -30° to +110°C


### Applications

Suitable for:

- Hydraulic fluids
- HFA fluids
- HFB fluids
- HFC fluids
- Air

### Info

- Ideal for use in the maintenance dept.

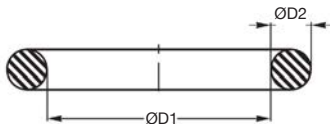

### Box contents

Quantity	ØD1	ØD2
25	7,65	1,78
25	9,25	1,78
25	12,42	1,78
25	15,60	1,78
20	18,77	1,78
15	23,52	1,78
10	29,87	1,78
10	37,82	1,78

### DISCOUNTS

Qty	1+	3+	5+
Disc.	Net	-5%	On request

Part N°	Material	Qty per box	Price each
BOX-TOR-ORFS	NBR 90 Sh A	155 pieces	35,77 €


All dimensions in mm

## Altri prodotti...



PM2

Coppia ruota e vite senza fine, Acciaio non temprato

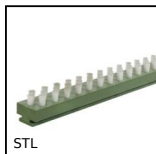

STL

Guida con spazzola, Spazzola



PTA100

Piede snodato con base stampata Ø100, Ø 100



TRM

Cremagliera sezione circolare, Acciaio - modulo 1-6



BTCW

Tappo inox per tubo quadrato, A saldare



D-PAR\_SS

Piedino antivibrante parabolico, inox



PW\_PWG15

Vite senza fine di precisione, Acciaio



R206

Molla per stampi ISO10243, Extra-forte



INS\_SS

Boccola autofilettante Inox, Inox



PW\_PWG1

Ruota di precisione, Bronzo



CPAS-H

Squadra pieghevole, Per carico pesante



LINK64

Motoriduttore AC sincrono, da 1.3 a 6Nm

## Prodotti correlati



BOX-TOR-TOOL

Valigetta di guarnizioni toriche in nitrile, Extraction tools