

O-Ring kit, NBR90Sh A

BOX-TOR-ORFSizes from 7.65x 1.78mm to 37.82x1.78mm

- Selection of O-Rings for ORF fittings
- 8 sizes
- Material:
Nitrile NBR 90 shore A
- Working temperature range: -30° to +110°C


Applications

Suitable for:

- Hydraulic fluids
- HFA fluids
- HFB fluids
- HFC fluids
- Air

Info

- Ideal for use in the maintenance dept.

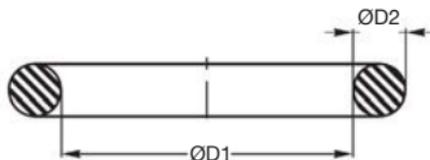

Box contents

Quantity	ØD1	ØD2
25	7,65	1,78
25	9,25	1,78
25	12,42	1,78
25	15,60	1,78
20	18,77	1,78
15	23,52	1,78
10	29,87	1,78
10	37,82	1,78

DISCOUNTS

Qty	1+	3+	5+
Disc.	Net	-5%	On request

Part N°	Material	Qty per box	Price each
BOX-TOR-ORFS	NBR 90 Sh A	155 pieces	35,77 €

All dimensions in mm

Altri prodotti...



Ingranaggio elicoidale ad assi paralleli, Plastica lavorata (delrin)



Piastra di giunzione per cinghia T, T10



Ruote per viti senza fine, Bronzo



Ingranaggio dritto Inox, Inox 304L



Vite senza fine , Acciaio temprato



Manicotto a sfere di precisione, Di precisione - acciaio



Economic mini-table with trapezoidal leadscrew, 2kg



Ruota di rinvio, Serie 880



Pignone a catena - Inox, 12.7mm (DIN 08B-1)



Sfera portante, Forte



Dado per viti a sfere, Dado flangiato a circuiti multipli



Riduttore a rinvio angolare a L o a T, fino a 75,7 Nm

Prodotti correlati



Valigetta di guarnizioni toriche in nitrile, Extraction tools