

# Box set of hose clamps

## BOX-CS

## Steel

- Boxes containing solid 9 and 12mm wide hose clamps
- Ideal for the maintenance department

### Info.

- Also contains a flexible screwdriver



### Small version BOX-CS-100

Quantity	Range of adjustment ØD	Collar width
15	8-12	9
20	10-16	9
20	12-22	9
15	16-27	9
15	20-32	9
15	25-40	9

### Large version BOX-CS-220

Quantity	Range of adjustment ØD	Collar width
20	8-12	9
25	10-16	9
30	12-22	9
25	16-27	9
25	20-32	9
25	25-40	9
20	16-27	12
20	20-32	12
20	32-50	12
10	40-60	12

### DISCOUNTS

Qty	1+	2+	5+
Disc. Prix	-5%		On request

Part N°	Box dimensions	Quantity per box	Price each
BOX-CS-100	255x315x65	100 clamps	59,84 €
BOX-CS-220	460x360x85	220 clamps	124,68 €


All dimensions in mm

## Altri prodotti...



SUA4\_L

Giunzione per catena al metro, Falsa maglia - acciaio

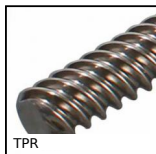

TPR

Madrevite a passo lungo, Madrevite solafino a 40mm di corsa per rot...



PTR

Pignone tendicatena, Per applicazioni correnti



ZG2

Ingranaggio dritto in plastica, Plastica lavorata (delrin)



DOMI30

Kit di raccordo, Kit di raccordo XZ



BLHT60

Rinvio angolare a T, da 26 a 70 Nm



PRF19\_E

Squadra di giunzione, PRF19 a PRF32



SLV

Attrezzo di bloccaggio a leva verticale, A leva verticale - inox



BLH30

Rinvio angolare a L, da 1.32 a 4.40 Nm



GLB

Volantino a 6 lobi filettato, Tecnopolimero - Inox



APB\_F

Perno di fissaggio per morsetti, Filettato



TBE12

Economic mini-table with trapezoidal leadscrew, 2kg

## Prodotti correlati



BOX-CSss

Fascette di serraggio, Valigetta di fascette inox