

Box set of hose clamps

Stainless steel

BOX-CS/SS

stainless steel

- Boxes containing solid 9 and 12mm wide hose clamps
- Ideal for the maintenance department

Info.

- Also contains a flexible screwdriver



Small version BOX-CS-100/SS

Quantity	Range of serrage Ø	largeur bande
15	8-12	9
20	10-16	9
20	12-22	9
15	16-27	9
15	20-32	9
15	25-40	9

Large version BOX-CS-220/SS

Quantity	Range of adjustment Ø	Collar width
20	8-12	9
25	10-16	9
30	12-22	9
25	16-27	9
25	20-32	9
25	25-40	9
20	16-27	12
20	20-32	12
20	32-50	12
10	40-60	12

DISCOUNTS

Qty	1+	2+	5+
Disc. Prix	-5%	-5%	On request

Part N°	Box dimensions	Quantity per box	Price each
BOX-CS-100/SS	255x315x65	100 clamps	97,25 €
BOX-CS-220/SS	460x360x85	220 clamps	184,03 €

All dimensions in mm

Fax 0 825 88 6000
Service 0,15 € / min
+ prix appel

cial2@hpceurope.com

HPC

SUPPLEMENT 2019

207

Altri prodotti...



EML
Volantino a lobi, Dado monoblocco



NIN
Dado autofrenante, Inox A2



SBS_L
Giunzione per catena al metro, Falsa maglia - inox



NSU
Supporto per sensore, Morsetto universale base a 90°



UCF_SS
Cuscinetto a flangia quadrata tutto inox, inox



F7-E
Visualizzatore multifunzione, Con sensore di posizione esterno



APB_T
Perno di fissaggio per morsetti, Maschiato




LVT
Mini martinetto motorizzato 2A, 2 ampere



PAT85
Piede snodato con base stampata Ø85, Ø



PCS75K
Pignone a catena dentatura temprata,

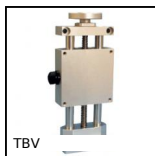

TBV
Tavola di posizionamento



GMK17_BR
Morsetto porta guide, Conico doppio

Prodotti correlati



BOX-CS
Fascette di serraggio, Valigetta di fascette acciaio