

O-Ring kit, NBR90Sh A

BOX-TOR-ORFSizes from 7.65x 1.78mm to 37.82x1.78mm

- Selection of O-Rings for ORF fittings
- 8 sizes
- Material:
Nitrile NBR 90 shore A
- Working temperature range: -30° to +110°C


Applications

Suitable for:

- Hydraulic fluids
- HFA fluids
- HFB fluids
- HFC fluids
- Air

Info

- Ideal for use in the maintenance dept.

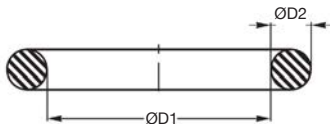

Box contents

| Quantity | ØD1 | ØD2 |
|----------|-------|------|
| 25 | 7,65 | 1,78 |
| 25 | 9,25 | 1,78 |
| 25 | 12,42 | 1,78 |
| 25 | 15,60 | 1,78 |
| 20 | 18,77 | 1,78 |
| 15 | 23,52 | 1,78 |
| 10 | 29,87 | 1,78 |
| 10 | 37,82 | 1,78 |

DISCOUNTS

| Qty | 1+ | 3+ | 5+ |
|-------|-----|-----|------------|
| Disc. | Net | -5% | On request |

| Part N° | Material | Qty per box | Price each |
|--------------|-------------|-------------|------------|
| BOX-TOR-ORFS | NBR 90 Sh A | 155 pieces | 35,77 € |

All dimensions in mm

Altri prodotti...



HW_HT

Guida su semi-binari,
Binario



MPB

Distanziatore
esagonale, Ottone



BPTR

Tappo per tubo tondo,
Standard



AC

Piastrina di riscontro,
15mm



P55

Riduttore a ruota e
vite senza fine, fino a
57 Nm



CHINV2

Cerniera invisibile,
Invisibile - Apertura
fino a 125°



HK

Accessorio di
serraggio manuale,
Serraggio manuale
LWH



LVT

Mini martinetto
motorizzato 4A, 4
ampere



PW_PWG2

Vite senza fine di
precisione, Inox



UCFL_SS

Cuscinetto a flangia
ovale tutto inox, Inox



SHSS

Vite a spalla inox 416,
Inox 416 pretrattato



BABtss

Perno autobloccante
inox 303, Inox 303

Prodotti correlati



BOX-TOR-TOOL

Valigetta di
guarnizioni toriche in
nitrile, Extraction
tools