

Ball transfer unit in blue certified plastic

Suitable for foodstuff sector

BPPEBLU



- The ball transfer units are made of a certified blue plastic which is suitable for use in the foodstuff sector
- Press-in assembly
- Conveying speed up to 1.5 m/s
- Foodstuff conform: Food Grade, EU Regulation 1935/2004, EU Regulation 10/2011
- Material :
 - Housing and cap POM
 - Bearing ball stainless steel
 - Load ball stainless steel or plastic
- Temperature range: -30 °C to +50 °C (up to +30°C with plastic load balls)

Advantages

- The ball transfer units are equipped with a gap-free and sealed cap, which prevents the formation of soiled edge
- The dirt holes underneath the housing enable particularly easy cleaning of the ball transfer units



Food industry
NEW!

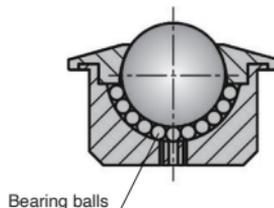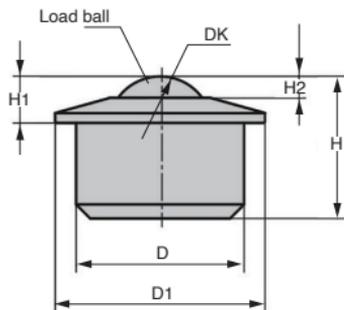

DISCOUNTS

Qty	1+	6+	20+	30+
Disc.	List	-10%	-15%	On request


Part number	ØD	ØD1	ØDK	H	H1	H2	Load rating C (kg)	Price each 1 to 5
Load ball in POM								
BPPE15-24/PP/BLU	24±0,1	31±0,2	15,875	20,5±0,2	9,5±0,2	4,5	200	
BPPE22-36/PP/BLU	36±0,1	45±0,2	22,225	30,5±0,2	10±0,2	4,5	250	
BPPE30-45/PP/BLU	45±0,1	55±0,1	30,000	37±0,1	14±0,1	5,5	350	
BPPE45-62/PP/BLU	62±0,1	75±0,1	44,500	53,5±0,1	19±0,1	9,0	500	
Load ball in stainless steel								
BPPE15-24/SS/BLU	24±0,1	31±0,2	15,875	20,5±0,2	9,5±0,2	4,5	200	
BPPE22-36/SS/BLU	36±0,1	45±0,2	22,225	30,5±0,2	10±0,2	4,5	250	
BPPE30-45/SS/BLU	45±0,1	55±0,1	30,000	37±0,1	14±0,1	5,5	350	
BPPE45-62/SS/BLU	62±0,1	75±0,1	44,500	53,5±0,1	19±0,1	9,0	500	

All dimensions in mm.

Altri prodotti...



Single output shaft,
For CHB gearbox

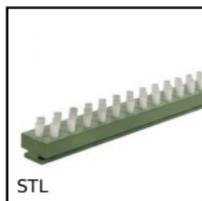

Guida con spazzola,
Spazzola



Inserto auto-
maschiante a passo
grosso, Filetto largo



Riduttore a ruota e
vite senza fine, fino a
8.80 Nm



Asse per morsetti,
Tappo di sicurezza



Sistema di chiusura,
Chiusura a molla



Cerniera ad avvitare
estetica asimmetrica,
Poliammide



Pressore liscio a
molla, Corpo
termoplastica



Vite trapezoidale
acciaio, Acciaio
semiduro - 1 filetto



Ruota per profili
alluminio, Girevole
con freno



Rinvio angolare a T,
da 4 a 10.30 Nm



Pressore a molla
sensore di
rilevamento, Con asta
di comando per int...

Prodotti correlati



Sfera portante,
Leggero



Sfera portante a
incastro, Leggero



Sfera portante a
incastro, Leggero



Sfera portante a
incastro con flangia,
Forte