

# Knurled tapped Torque Knob

## Adjustable torque

## BSC

- **Knurled knob with coloured insert**
- **Materials:**  
Dark grey thermoplastic  
Tapped insert: black oxidised steel 5.8




### Info.

- The required torque is adjusted by means of a screw.
- As soon as this torque is reached, the knurled knob will start to slip.

### Options

- Versions with different coloured inserts are available, signal red, dark grey, yellow

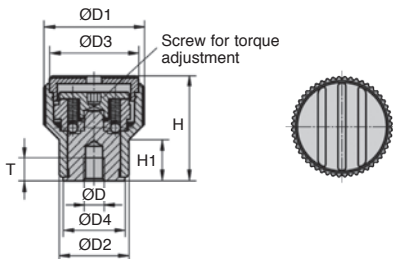

Same tightening torque

### DISCOUNTS

Qty	1+	6+	10+	25+
Disc.	List	-5%	-10%	On request

Part number	ØD	ØD1	ØD2	ØD3	ØD4	H	H1	T	Torque range (Nm)	Price each 1 to 5
<b>Grey insert</b>										
BSC26-M5	M5	26	18	23	16	27	10,5	5	0,1 - 0,3	44,38 €
BSC26-M6	M6	26	18	23	16	27	10,5	6	0,1 - 0,3	44,38 €
BSC34-M6	M6	34	22	31	20	37,5	14,5	10	0,1 - 0,3	48,96 €
BSC34-M8	M8	34	22	31	20	37,5	14,5	14	0,1 - 0,3	48,96 €

Dimensions in mm

**0 825 88 6000**  
Service 0,15 € / min  
+ prix appel

Fax

cial2@hpceurope.com

**HPC**

SUPPLEMENT 2019

141

## Altri prodotti...



GLT2-17

Guide telescopiche per montaggio in scanalatura, Estensione parziale



BLHM40

Rinvio angolare, fino a 10.3 Nm



BCM\_T

Elemento di trascinamento, Elemento di trascinamento




ACL-PL

Elementi di giunzione, Piastra di fissaggio - 176x86 mm




AT10-32ECO

Puleggia dentata di posizionamento tipo AT, Serie economica - AT10 a...

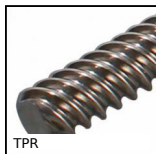

TPR

Madrevite a passo lungo, Madrevite sola fino a 40mm di corsa per rot...

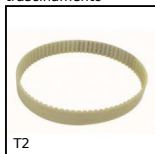

T2

Cinghia di posizionamento T, T2.5 Poliuretano armatura in acciaio



PDM\_PDV

Detectable plastic palm grip, by metal detectors



BPLE

Sfera portante a incastro, Leggero



BLH60

Rinvio angolare a L, da 19 a 70 Nm



HLUss

Volantino a razze, Inox 316



PCS37K

Pignone a catena dentatura temprata, 9.525mm (DIN06B-1)

## Prodotti correlati



BSCm

Manopola, Con coppia regolabile