

# Knurled tapped Torque Knob

## Adjustable torque

## BSC

- **Knurled knob with coloured insert**
- **Materials:**  
Dark grey thermoplastic  
Tapped insert: black oxidised steel 5.8




### Info.

- The required torque is adjusted by means of a screw.
- As soon as this torque is reached, the knurled knob will start to slip.

### Options

- Versions with different coloured inserts are available, signal red, dark grey, yellow

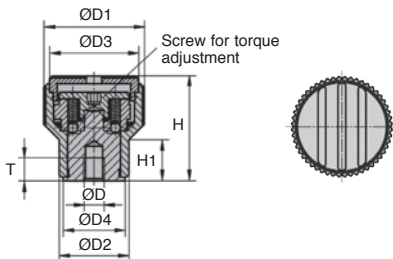

Same tightening torque

### DISCOUNTS

Qty	1+	6+	10+	25+
Disc. List	-5%	-10%	On request	

Part number	ØD	ØD1	ØD2	ØD3	ØD4	H	H1	T	Torque range (Nm)	Price each 1 to 5
<b>Grey insert</b>										
BSC26-M5	M5	26	18	23	16	27	10,5	5	0,1 - 0,3	44,38 €
BSC26-M6	M6	26	18	23	16	27	10,5	6	0,1 - 0,3	44,38 €
BSC34-M6	M6	34	22	31	20	37,5	14,5	10	0,1 - 0,3	48,96 €
BSC34-M8	M8	34	22	31	20	37,5	14,5	14	0,1 - 0,3	48,96 €

Dimensions in mm

**0 825 88 6000**  
Service 0,15 € / min  
+ prix appel

Fax

cial2@hpceurope.com

**HPC**

SUPPLEMENT 2019

141

## Altri prodotti...



CHAR16046

Cerniera a molla,  
avvitabile



SUPCC

Calettatore di  
bloccaggio  
autocentrante acciaio,  
Con ghiera



PSG15

Ingranaggio dritto di  
precisione, Acciaio  
20NCD2 cementato  
 temprato



PSG35

Ingranaggio dritto di  
precisione, Inox 303



NTM

Grano punta in nylon,  
punta in nylon



SLHHlok

Bloccaggio a leva, A  
leva orizzontale / base  
orizzontale



NKIB

Cuscinetto combinato  
con anello interno,  
Carico assiale  
bidirezionale



FF15

Riduttore ad alberi  
paralleli, da 2.20 a 10  
Nm




P70

Riduttore a ruota e  
vite senza fine, fino a  
164 Nm



ZBconique

Ingranaggio conico in  
plastica, 1:1

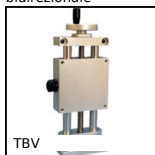

TBV

Tavola di  
posizionamento  
verticale manuale,



TRMSS

Cremaiera a sezione  
circolare, Inox -  
modulo 1-5

## Prodotti correlati



BSCm

Manopola, Con coppia  
regolabile