

Knurled tapped Torque Knob

Adjustable torque

BSC

 

- **Knurled knob with coloured insert**
- **Materials:**
 - Dark grey thermoplastic
 - Tapped insert: black oxidised steel 5.8

Info.


- The required torque is adjusted by means of a screw.
- As soon as this torque is reached, the knurled knob will start to slip.

Options

- Versions with different coloured inserts are available, signal red, dark grey, yellow

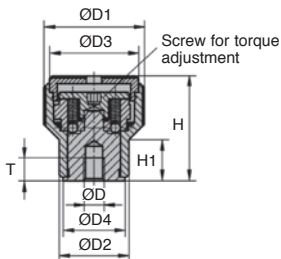

Easily unscrewed
by anyone

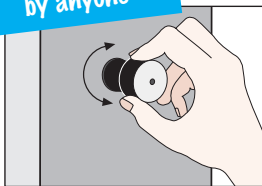

Same tightening torque

DISCOUNTS

Qty	1+	6+	10+	25+
Disc. List	-5%	-10%	On request	

Part number	ØD	ØD1	ØD2	ØD3	ØD4	H	H1	T	Torque range (Nm)	Price each 1 to 5
Grey insert										
BSC26-M5	M5	26	18	23	16	27	10,5	5	0,1 - 0,3	44,38 €
BSC26-M6	M6	26	18	23	16	27	10,5	6	0,1 - 0,3	44,38 €
BSC34-M6	M6	34	22	31	20	37,5	14,5	10	0,1 - 0,3	48,96 €
BSC34-M8	M8	34	22	31	20	37,5	14,5	14	0,1 - 0,3	48,96 €

Dimensions in mm

0 825 88 6000
Service 0,15 € / min
+ prix appel

Fax

cial2@hpceurope.com

HPC

SUPPLEMENT 2019

141

Altri prodotti...



HBM

Guida su semi-binari,
Boccola di regolazione



BAG55

Anello di bloccaggio
inox, Inox



FGWA

Supporto per
estremità dell'albero,
A soletta



PDM_PDV

Detectable plastic
palm grip, blue
thermoplastic



PSG05

Ingranaggio dritto di
precisione, Acciaio
35NCD6 pretrattato



DER63

Motore inox AC
asincrono 0,18kW,
0.18kW



KBS_UU

Manicotto chiuso a
sfere inox di
precisione, Di
precisione - inox / ...



PTAF100-PAMF100

Piede fissabile con
base lamiera Ø100, Ø
100



SSG1_304L

Ingranaggio dritto
Inox, Inox 304L



H1

Ingranaggio elicoidale
ad assi incrociati a



WINGbrEcrou

Dado ad alette per
serraggio manuale



NSA

Connettore rinvio
d'angolo, Articolato

Prodotti correlati



BSCm

Manopola, Con coppia
regolabile