

Knurled threaded torque Knob

BSC

Adjustable torque

- **Knurled knob with coloured insert**

- **Materials:**

Dark grey thermoplastic


Thread: steel blue chromed

Info.

- The required torque is adjusted by means of a screw.
- As soon as this torque is reached, the knurled knob will start to slip.

Options

- Versions with different coloured inserts are available, signal red, dark grey, yellow

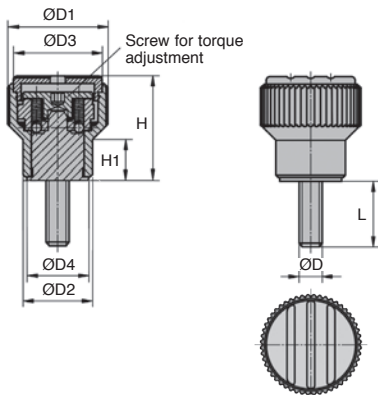

DISCOUNTS

Qty	1+	6+	10+	25+
Disc.	List	-5%	-10%	On request

Part number	ØD	L	ØD1	ØD2	ØD3	ØD4	H	H1	T	Torque range (Nm)	Price each 1 to 5
Grey insert											
BSC26-M5-30	M5	30	26	18	23	16	27	10,5	5	0,1 - 0,3	45,16 €
BSC26-M5-50	M5	50	26	18	23	16	27	10,5	5	0,1 - 0,3	45,42 €
BSC26-M6-30	M6	30	26	18	23	16	27	10,5	6	0,1 - 0,3	45,16 €
BSC34-M6-40	M6	40	34	22	31	20	37,5	14,5	10	0,1 - 0,3	71,14 €
BSC34-M6-50	M6	50	34	22	31	20	37,5	14,5	10	0,1 - 0,3	45,42 €
BSC34-M6-60	M6	60	34	22	31	20	37,5	14,5	10	0,1 - 0,3	50,15 €
BSC34-M8-40	M8	40	34	22	31	20	37,5	14,5	14	0,1 - 0,3	49,78 €
BSC34-M8-60	M8	60	34	22	31	20	37,5	14,5	14	0,1 - 0,3	50,15 €

Dimensions in mm

Altri prodotti...



BPLE
Sfera portante a
incastro, Leggero



RBNpl
Ruota girevole con
piastra, Acciaio -
caucciù



GLT3-46
Guide telescopiche
acciaio, Estensione
totale



NCT
Giunto di
collegamento, Ad
angolo fisso



E15
Riduttore a rinvio
angolare, da 0.40 a
2.53 Nm



RVM14
Riduttore manuale, A
ruota e vite senza fine



CHAEpac
Square decorative
screwed hinges,
carbon fibre
reinforced



PRF_FIX_STD
Fissaggio, Fissaggio
standard



DB
Ingranaggio conico -
Acciaio 60C40, 2:1



ZHG5
Ingranaggio dritto in
plastica, Plastica
lavorata (delrin)



BABTV
Ball lock pins lockable
, Stainless steel



KBS_UU
Manicotto chiuso a
sfere inox di
precisione, Di
precisione - inox / ...

Prodotti correlati



BSCf
Manopola, Con coppia
regolabile