

New

Motor gearboxes 12 and 24 Vdc

Torque from 0.1 to 2 Nm

BUH77

- Gearbox type : spur gear
- Bearing : bronze
- Max axial load : 10N
- Max radial load : 30N at 5mm from flange
- Angular backlash : 0.05 to 0.6mm
- Working temp : from -10° to 70°C
- Weight : 250g

Application


- Drives, ideal for Start/Stop applications or reverse applications

Advantages

- Compact size
- High torque

Accessories

- Servoamplifier: **NANODC-1A-30/3** (speed controller)
- Power supply **ALIDR30-12, ALIDR30-24**

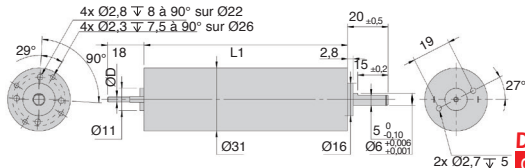**NEW!**

DISCOUNTS

Qty	1+	6+	10+
Disc Price		-7%	on request

Part number	Reduction	N° of stages	ØD	L1 (mm)	No-load speed (rpm)	Speed under load (rpm)	Nominal torque (Nm)	Nominal current (A)	Price each
12V DC Version									
BUH77-12-004	3,4	1	3	100,5	1215	900	0,10	1,4	174,80 €
BUH77-12-012	11,6	2	3	106,6	355	260	0,30	1,4	174,80 €
BUH77-12-022	21,4	2	3	106,6	190	140	0,55	1,4	174,80 €
BUH77-12-040	39,7	2	3	106,6	105	75	1,00	1,4	183,33 €
BUH77-12-135	135	3	2,5	88,5	33	23	1,80	0,85	183,33 €
BUH77-12-250	250	3	2,5	88,5	18	14	2,00	0,85	183,33 €
24V DC Version									
BUH77-24-004	3,4	1	3	100,5	1215	900	0,10	0,7	174,80 €
BUH77-24-012	11,6	2	3	106,6	355	260	0,30	0,7	174,80 €
BUH77-24-022	21,4	2	3	106,6	190	140	0,55	0,7	185,46 €
BUH77-24-040	39,7	2	3	106,6	105	75	1,00	0,7	185,46 €
BUH77-24-135	135	3	2,5	88,5	33	23	1,80	0,425	185,46 €
BUH77-24-250	250	3	2,5	88,5	18	14	2,00	0,275	185,46 €

Dimensions in mm

Altri prodotti...



T10_30_AL

Puleggia dentata di posizionamento tipo T, Serie economica - T10 all...




PRF-SRA

Sistema di chiusura per profili alluminio, Serrata



SHWbr

Rondella semplice - DIN125, Ottone

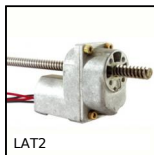

LAT2

Attuatore lineare a motore 2A, 2 ampere



MBEX

Riduttore manuale, Manovella estremità esagonale



NPTR

Morsetto, Regolabile



CHA1056_U4

Cerniera ad avvitare, Sezione 40X40



DOMI50

Accessori di collegamento, Piatto girevole



BCFH

Pomello a fungo Hygienic Usit®, Con



CHAC4040NP

Cerniera, Quadrata con rivetto senza fori



PRFRTR

Elementi di giunzione, Giunto di



PTCR

Adjustable furniture foot, square tube

Prodotti correlati



NANO

Variatore di velocità 3A, 3 A



ALIDR30

Alimentazione, 1,5 A and 2 A