

**New**

# Motor gearboxes 12 and 24 Vdc

Torque from 0.1 to 2 Nm

**BUH77**

- Gearbox type : spur gear
- Bearing : bronze
- Max axial load : 10N
- Max radial load : 30N at 5mm from flange
- Angular backlash : 0.05 to 0.6mm
- Working temp : from -10° to 70°C
- Weight : 250g

## Application

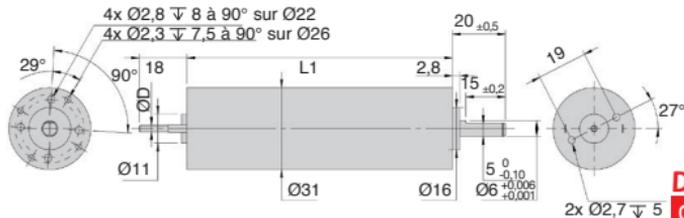
- Drives, ideal for Start/Stop applications or reverse applications

## Advantages

- Compact size
- High torque

## Accessories

- Servoamplifier: **NANODC-1A-30/3** (speed controller)
- Power supply **ALIDR30-12**, **ALIDR30-24**

**NEW!**

## DISCOUNTS

Qty	1+	6+	10+
Disc Price		-7%	on request

Part number	Reduction	N° of stages	ØD	L1 (mm)	No-load speed (rpm)	Speed under load (rpm)	Nominal torque (Nm)	Nominal current (A)	Price each
<b>12V DC Version</b>									
BUH77-12-004	3,4	1	3	100,5	1215	900	0,10	1,4	174,80 €
BUH77-12-012	11,6	2	3	106,6	355	260	0,30	1,4	174,80 €
BUH77-12-022	21,4	2	3	106,6	190	140	0,55	1,4	174,80 €
BUH77-12-040	39,7	2	3	106,6	105	75	1,00	1,4	183,33 €
BUH77-12-135	135	3	2,5	88,5	33	23	1,80	0,85	183,33 €
BUH77-12-250	250	3	2,5	88,5	18	14	2,00	0,85	183,33 €
<b>24V DC Version</b>									
BUH77-24-004	3,4	1	3	100,5	1215	900	0,10	0,7	174,80 €
BUH77-24-012	11,6	2	3	106,6	355	260	0,30	0,7	174,80 €
BUH77-24-022	21,4	2	3	106,6	190	140	0,55	0,7	185,46 €
BUH77-24-040	39,7	2	3	106,6	105	75	1,00	0,7	185,46 €
BUH77-24-135	135	3	2,5	88,5	33	23	1,80	0,425	185,46 €
BUH77-24-250	250	3	2,5	88,5	18	14	2,00	0,275	185,46 €

Dimensions in mm

## Altri prodotti...



TFR

Tenditore rigido, Fisso



BPTR\_M

Tappo per tubo, Con  
inserto maschiato



ACM\_DZ

Base per tirante  
chiusura in gomma,  
Base



CHT

Motore AC asincrono  
trifase, 0.55 a 1.1kW



PSP

Accessori per  
pannello, Profilo  
supporto per pannelli



LVT

Mini martinetto  
motorizzato 1A, 1  
ampere



BAC105

Contenitore a becco,  
8mm



PM4

Ruota per vite senza  
fine, Bronzo



PRF\_GAL

Rotella per profilo  
alluminio, Rotella  
liscia



CHAFR

Cerniera, A frizione



CAP820

Catena a tapparella  
dritta, Stretta serie  
820



SC2

Giunto rigido in 2  
parti, Ganascia di  
serraggio

## Prodotti correlati



NANO

Variatore di velocità  
3A, 3 A



ALIDR30

Alimentazione, 1,5 A  
and 2 A